




## NVENT CADDY ALL-IN-ONE BETWEEN-STUD WITHOUT MUD RING, MULTI-BOX

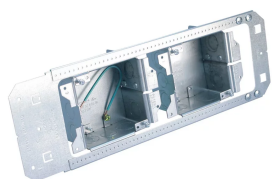

### CERTIFICATIONS



### FEATURES

Comes with multiple boxes pre-assembled for side by side power and data applications

Provides the flexibility to add a mud ring for non-standard drywall thicknesses

Box remains fixed in place when mud ring is removed

Pre-bent tabs on support bracket help to quickly square assembly to stud

Center marks provide easy height positioning

Includes multiple knockouts on each side of the box

Works with standard US and Canadian mud rings

### SPECIFICATIONS

**Finish:** Pregalvanized

**Material:** Steel

Table 1/2

Catalog Number	Knockout Sizes, Box 1	Knockout Sizes, Box 2	Ground Wire Included, Box 1	Volume, Box 1	Ground Wire Included, Box 2	Volume, Box 2
A1BF0GD0NS	(8) 1/2", 3/4"	(5) 1/2", 3/4", (1) 1/2", (3) 1"	Yes	32.8in <sup>3</sup>	No	32.8in <sup>3</sup>
A1BF0G40N	(8) 1/2", 3/4", (3) 1/2"	(4) 1", (4) 1 1/4"	Yes	32.8in <sup>3</sup>	No	42in <sup>3</sup>
A1BF0GD0N	(8) 1/2", 3/4"	(5) 1/2", 3/4", (1) 1/2", (3) 1"	Yes	32.8in <sup>3</sup>	No	32.8in <sup>3</sup>

Table 2/2

Catalog Number	Stud Spacing	Depth (D)	A	B
A1BF0GD0NS	16" - 24"	2 1/2"	5 3/8"	4 1/8"
A1BF0G40N	16" - 24"	3 5/8"	5 3/8"	4 1/8"
A1BF0GD0N	16" - 24"	3 5/8"	5 3/8"	4 1/8"

 
 
## ADDITIONAL PRODUCT DETAILS

Ground wire pigtail is 10".

24" stud spacing requires use of three mounting screws.

Use only with nVent CADDY All-in-One box assemblies.

## DIAGRAMS



## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**