




NVENT CADDY ALL-IN-ONE STUD-MOUNTED WITHOUT MUD RING

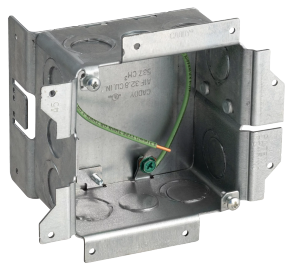

CERTIFICATIONS



FEATURES

- Provides the flexibility to add a mud ring for non-standard drywall thicknesses
- Box remains fixed in place when mud ring is removed
- Includes multiple knockouts on each side of the box
- Assemblies keyed for precise alignment when installed on both sides of a stud
- Works with standard US and Canadian mud rings

SPECIFICATIONS

- Finish:** Pregalvanized
- Material:** Steel

Table 1/2						
Catalog Number	Knockout Sizes	Ground Wire Included	Back Plate Pre-assembled	Box Volume	Depth (D)	A
A1SD0NS	(5) 1/2", 3/4", (1) 1/2", (3) 1"	No	Yes	32.8in ³	2 1/2"	5 3/4"

Catalog Number	Knockout Sizes	Ground Wire Included	Back Plate Pre-assembled	Box Volume	Depth (D)	A
A1SF0GS	(8) 1/2", 3/4", (3) 1 1/2"	Yes	Yes	32.8in ³	2 1/2"	5 3/4"
A1SF0GSBUSH250	(8) 1/2", 3/4", (3) 1 1/2"	Yes	No	32.8in ³	2 1/2"	5 3/4"
A1SD0G	(5) 1/2", 3/4", (1) 1 1/2", (3) 1"	Yes	Yes	32.8in ³	3 5/8"	5 3/4"
A1SF0G	(8) 1/2", 3/4", (3) 1 1/2"	Yes	Yes	32.8in ³	3 5/8"	5 3/4"
A1SF0GBUSH250	(8) 1/2", 3/4", (3) 1 1/2"	Yes	No	32.8in ³	3 5/8"	5 3/4"
A1SF0N	(8) 1/2", 3/4", (3) 1 1/2"	No	Yes	32.8in ³	3 5/8"	5 3/4"


Table 2/2

Catalog Number	B	Packing Quantity
A1SD0NS	5 1/8"	1.0000
A1SF0GS	5 1/8"	1.0000
A1SF0GSBUSH250	5 1/8"	1.0000
A1SD0G	5 1/8"	1.0000
A1SF0G	5 1/8"	1.0000
A1SF0GBUSH250	5 1/8"	1.0000
A1SF0N	5 1/8"	1.0000

ADDITIONAL PRODUCT DETAILS

Ground wire pigtail is 10".

DIAGRAMS

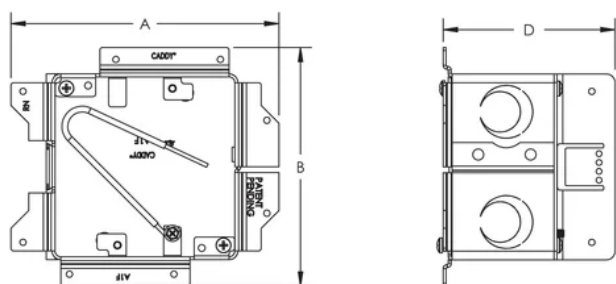

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER