




NVENT CADDY HEAVY DUTY TELESCOPING BRACKET BETWEEN STUD ASSEMBLY

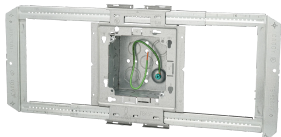

The nVent CADDY Heavy Duty Telescoping Bracket Between Stud Assembly line increases overall productivity, savings, and job site safety. For ultimate flexibility, the assemblies are configured with the most common box and mud ring combinations. The line is also offered in both standard and open back boxes as well as in single and double gang fixed or adjustable depth mud rings. When paired with the nVent CADDY Open Back Box, the assembly is ideal for prefab installations where devices, fittings, and cables are installed to quickly and easily complete make-up wiring connections, without the need to drop or work through the mud ring.

CERTIFICATIONS



FEATURES

- Rigid and versatile - add/remove boxes quickly and easily
- Prefab tab to prevent disassembly during transport, but allows for sliding on main bracket prior to final securement
- Bracket will telescope and allow for easy positioning within wall stud
- Box center plates slide to desired position prior to final securement

SPECIFICATIONS

- Stud Spacing:** 14 1/2" - 25"
- Finish:** Pregalvanized
- Material:** Steel

Table 1/3						
Catalog Number	Knockout Sizes, Box 1	Knockout Sizes, Box 2	Box Depth	Box Size 1	Box Size 2	Box Type
TBP4DV2	(4) 1/2", 3/4", (8) 1/2"		2 1/8"	4		Closed

Catalog Number	Knockout Sizes, Box 1	Knockout Sizes, Box 2	Box Depth	Box Size 1	Box Size 2	Box Type
TBP4DM1	(4) 1/2", 3/4", (8) 1/2"		2 1/8"	4		Closed
TBP4DM1PP1M5	(4) 1/2", 3/4", (8) 1/2"	(12) 1/2", 3/4"	2 1/8"	4	4 11/16"	
TBPX4M1	(4) 1/2", 3/4", (7) 1/2"		2 1/8"	4		Open
TBP4DM2	(4) 1/2", 3/4", (8) 1/2"		2 1/8"	4		Closed
TBP4DV1	(4) 1/2", 3/4", (8) 1/2"		2 1/8"	4		Closed
TBPX4V1	(4) 1/2", 3/4", (7) 1/2"		2 1/8"	4		Open
TBP4D	(4) 1/2", 3/4", (8) 1/2"		2 1/8"	4		Closed
TBP4DPD1	(4) 1/2", 3/4", (8) 1/2"	(4) 1", (4) 1 1/4"	2 1/8"	4	4 11/16"	Closed
TBP4DPP1	(4) 1/2", 3/4", (8) 1/2"	(12) 1/2", 3/4"	2 1/8"	4	4 11/16"	Closed
TBPX4	(4) 1/2", 3/4", (7) 1/2"		2 1/8"	4		Open

Table 2/3						
Catalog Number	Drywall Thickness	Gang, Box 1	Gang, Box 2	Ground Wire Included	Mud Ring Type	Volume, Box 1
TBP4DV2	1/2" - 1 1/2"	2		Yes	Adjustable	30.3in ³
TBP4DM1	5/8"	1		Yes	Raised	30.3in ³
TBP4DM1PP1M5	5/8"	1	1	Yes	Raised	30.3in ³
TBPX4M1	5/8"	1		Yes	Raised	32.8in ³
TBP4DM2	5/8"	2		Yes	Raised	30.3in ³
TBP4DV1	5/8" - 1 1/2"	1		Yes	Adjustable	30.3in ³
TBPX4V1	5/8" - 1 1/2"	1		Yes	Adjustable	32.8in ³
TBP4D				Yes		30.3in ³
TBP4DPD1				Yes		30.3in ³
TBP4DPP1				Yes		30.3in ³
TBPX4				Yes		32.8in ³

Table 3/3	
Catalog Number	Volume, Box 2

TBP4DV2	
TBP4DM1	
TBP4DM1PP1M5	42in ³
TBPX4M1	
TBP4DM2	
TBP4DV1	
TBPX4V1	
TBP4D	
TBP4DPD1	42in ³
TBP4DPP1	42in ³
TBPX4	

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER