



# NVENT CADDY PYRAMID TOOL-FREE PIPE SUPPORT KIT



## FEATURES

- Push-in clamps install without the need for additional tools or strut clamps
- Ready to use out of the box, saving installation time and labor
- Plastic clamps and base will not corrode pipe
- Clamps come in two different sizes to fit project needs
- Base includes multiple holes to accommodate a variety of clamp sizes and configurations
- Additional clamps can be purchased separately for additional pipe runs
- Foam bottom offers low abrasion interface for better roof membrane protection
- Provides superior load distribution, even with varying rooftop surfaces
- Compatible with roof surfaces including single ply, bituminous, metal and spray foam
- Multiple sizes and load ratings offer the ability to tailor the solution to the application
- Easy to transport to the roof

## SPECIFICATIONS

- Static Load Safety Factor:** 3:1
- Material:** Polyethylene;Polypropylene;Nylon
- Temperature:** -50 to 150 °F

Table 1/2

Catalog Number	Length 1 (L1)	Length 2 (L2)	Length 3 (L3)	Width (W)	Height (H)	A
PTF6	7.72"		3.19	5.91"	4.02"	4.8"

Catalog Number	Length 1(L1)	Length 2(L2)	Length 3(L3)	Width (W)	Height (H)	A
PTF10	12.52"	4.8"	6.42	7.91"	4.02"	8"
PTF16	18.9"	7.99"	9.61	7.91"	4.02"	11.22"

Table 2/2

Catalog Number	B	Surface Area	Unit Weight	Static Load (F)
PTF6	1.61"	41in <sup>2</sup>	0.6 lb	300lb
PTF10	1.61"	92in <sup>2</sup>	1 lb	1000lb
PTF16	1.61"	142in <sup>2</sup>	2 lb	1500lb


## ADDITIONAL PRODUCT DETAILS

Length 2 represents maximum pipe center to pipe center using PTF2C clamps. Length 3 represents maximum pipe center to pipe center using PTF1C clamps.

Tool-Free Pipe Clamp					
Part Number	Outer Diameter OD		A	B	C
PTF1C	0.50" – 1.32"		3/8"	1.6"	3/4"
PTF2C	0.84" – 2.38"		3/8"	3.2"	3/4"

Part Number	Number of Clamps Included		Maximum Clamp Capacity	
	PTF1C	PTF2C	PTF1C	PTF2C
PTF6	1	1	3	1
PTF10	-	2	5	2
PTF16	-	2	7	3

DIAGRAMS

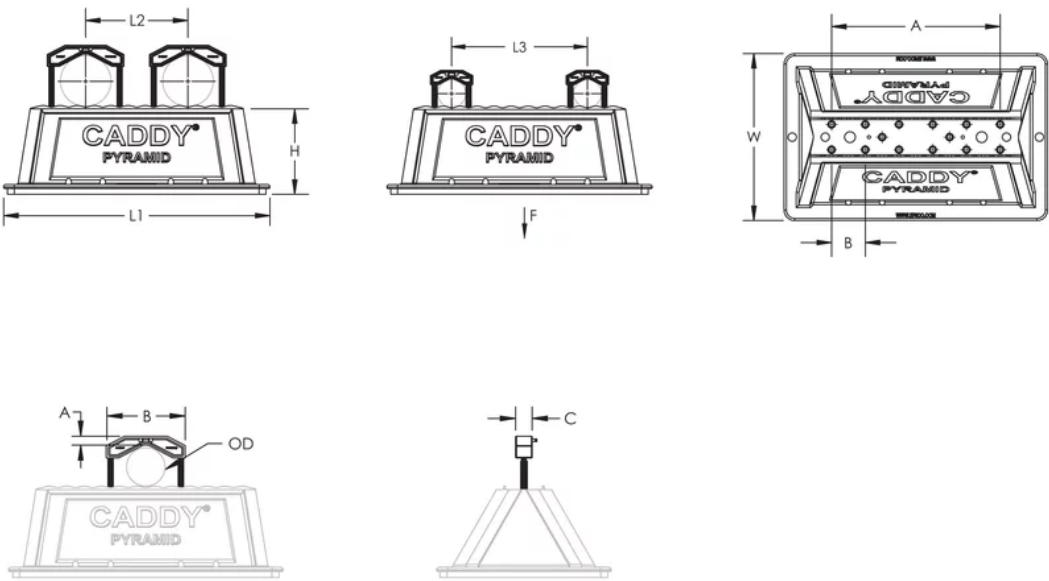

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**  
+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

**Europe**  
Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**  
Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**  
Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**