



## NVENT CADDY SPEED LINK SLK WITH HOOK



### CERTIFICATIONS



### FEATURES

Complete system includes wire, locking device and pre-assembled hook end fitting

Hooks to a wide range of nVent CADDY fasteners

Fastens to the building structure or hanging services by looping around and hooking to wire rope

Easy to remove for applications requiring maintenance

Spring latch helps provide secure connection

Insert cable through hole and use bottom side of hook as an end stop

Also available in Y-hook configuration

### SPECIFICATIONS

<b>Static Load Safety Factor:</b>	5:1
<b>Finish:</b>	Electrogalvanized
<b>Material:</b>	Steel; Polypropylene; Zinc Alloy
<b>Complies With:</b>	SMACNA HVAC-DCS

Table 1/2


Catalog Number	Wire Rope Diameter	Wire Rope Length	A	B	C	Height (H)
SLK15L1	1.5 mm	3.3'	1.89"	0.71"	0.18"	2.15"
SLK15L10	1.5 mm	32.8'	1.89"	0.71"	0.18"	2.15"
SLK15L2	1.5 mm	6.6'	1.89"	0.71"	0.18"	2.15"
SLK15L2R2	1.5 mm	6.6'	1.89"	0.71"	0.18"	2.15"
SLK15L3	1.5 mm	9.9'	1.89"	0.71"	0.18"	2.15"
SLK15L3R2	1.5 mm	9.9'	1.89"	0.71"	0.18"	2.15"
SLK15L5	1.5 mm	16.4'	1.89"	0.71"	0.18"	2.15"
SLK15L5R2	1.5 mm	16.4'	1.89"	0.71"	0.18"	2.15"
SLK2L1	2 mm	3.3'	2.24"	0.87"	0.22"	2.15"
SLK2L10	2 mm	32.8'	2.24"	0.87"	0.22"	2.15"
SLK2L2	2 mm	6.6'	2.24"	0.87"	0.22"	2.15"
SLK2L2R2	2 mm	6.6'	2.24"	0.87"	0.22"	2.15"
SLK2L3	2 mm	9.9'	2.24"	0.87"	0.22"	2.15"
SLK2L3R2	2 mm	9.9'	2.24"	0.87"	0.22"	2.15"
SLK2L5	2 mm	16.4'	2.24"	0.87"	0.22"	2.15"
SLK2L7	2 mm	22.9'	2.24"	0.87"	0.22"	2.15"
SLK3L1	3 mm	3.3'	2.27"	0.91"	0.24"	2 1/2"
SLK3L10	3 mm	32.8'	2.27"	0.91"	0.24"	2 1/2"
SLK3L2	3 mm	6.6'	2.27"	0.91"	0.24"	2 1/2"
SLK3L3	3 mm	9.9'	2.27"	0.91"	0.24"	2 1/2"
SLK3L3R2	3 mm	9.9'	2.27"	0.91"	0.24"	2 1/2"
SLK3L5	3 mm	16.4'	2.27"	0.91"	0.24"	2 1/2"
SLK3L5R2	3 mm	16.4'	2.27"	0.91"	0.24"	2 1/2"

Table 2/2

Catalog Number	Width (W)	Thickness (T)	Angle (a)	Packing Quantity	Certifications
SLK15L1	3/4"	1/2"	90 ° Max	1.0000	cUL, UL, SMACNA
SLK15L10	3/4"	1/2"	90 ° Max	1.0000	cUL, UL, SMACNA
SLK15L2	3/4"	1/2"	90 ° Max	1.0000	cUL, UL, SMACNA
SLK15L2R2	3/4"	1/2"	90 ° Max	2.0000	cUL, UL, SMACNA
SLK15L3	3/4"	1/2"	90 ° Max	1.0000	cUL, UL, SMACNA
SLK15L3R2	3/4"	1/2"	90 ° Max	2.0000	cUL, UL, SMACNA
SLK15L5	3/4"	1/2"	90 ° Max	1.0000	cUL, UL, SMACNA

CatalogNumber	Width (W)	Thickness (T)	Angle (a)	Packing Quantity	Certifications
SLK15L5R2	3/4"	1/2"	90 ° Max	2.0000	cUL, UL, SMACNA
SLK2L1	3/4"	1/2"	90 ° Max	1.0000	cUL, UL, SMACNA
SLK2L10	3/4"	1/2"	90 ° Max	1.0000	cUL, UL, SMACNA
SLK2L2	3/4"	1/2"	90 ° Max	1.0000	cUL, UL, SMACNA
SLK2L2R2	3/4"	1/2"	90 ° Max	2.0000	cUL, UL, SMACNA
SLK2L3	3/4"	1/2"	90 ° Max	1.0000	cUL, UL, SMACNA
SLK2L3R2	3/4"	1/2"	90 ° Max	2.0000	cUL, UL, SMACNA
SLK2L5	3/4"	1/2"	90 ° Max	1.0000	cUL, UL, SMACNA
SLK2L7	3/4"	1/2"	90 ° Max	1.0000	cUL, UL, SMACNA
SLK3L1	0.9"	0.6"	90 ° Max	1.0000	SMACNA
SLK3L10	0.9"	0.6"	90 ° Max	1.0000	SMACNA
SLK3L2	0.9"	0.6"	90 ° Max	1.0000	SMACNA
SLK3L3	0.9"	0.6"	90 ° Max	1.0000	SMACNA
SLK3L3R2	0.9"	0.6"	90 ° Max	2.0000	SMACNA
SLK3L5	0.9"	0.6"	90 ° Max	1.0000	SMACNA
SLK3L5R2	0.9"	0.6"	90 ° Max	2.0000	SMACNA

## DIAGRAMS

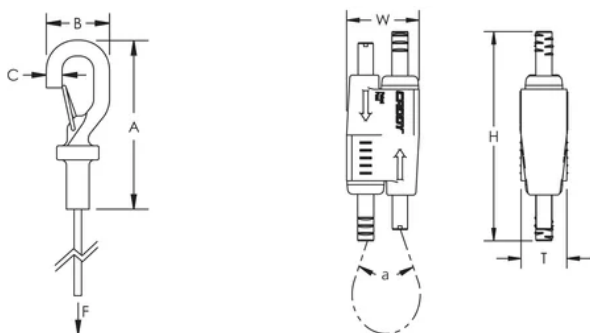

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**