



NVENT CADDY SPEED LINK SLK WITH TOGGLE



CERTIFICATIONS



FEATURES

- Complete system includes wire, locking device and pre-assembled toggle end fitting
- Attaches to clearance holes in a variety of structures or hanging devices
- Ideal for supporting lighting fixtures
- Also available in Y-toggle configuration

SPECIFICATIONS


Wire Rope Diameter:	1.5 mm
Static Load Safety Factor:	5:1
Finish:	Electrogalvanized
Material:	Steel;Zinc Alloy;Polypropylene
Complies With:	SMACNA HVAC-DCS

Table 1/1					
Catalog Number	Wire Rope Length	A	B	Static Load (F)	Packing Quantity
SLK15L10T	32.8'	1.54"	0.2"	44lb	1.0000

CatalogNumber	Wire Rope Length	A	B	Static Load (F)	Packing Quantity
SLK15L1T	3.3'	1.54"	0.2"	44lb	1.0000
SLK15L1TR2	3.3'	1.54"	0.2"	44lb	2.0000
SLK15L2T	6.6'	1.54"	0.2"	44lb	1.0000
SLK15L2TR2	6.6'	1.54"	0.2"	44lb	2.0000
SLK15L3T	9.9'	1.54"	0.2"	44lb	1.0000
SLK15L3TR2	9.9'	1.54"	0.2"	44lb	2.0000
SLK15L5T	16.4'	1.54"	0.2"	44lb	1.0000
SLK15L7T	22.9'	1.54"	0.2"	44lb	1.0000

Thickness (T): 1/2"
Width (W): 3/4"
Height (H): 2.15"
Angle (a): 90 ° Max

DIAGRAMS

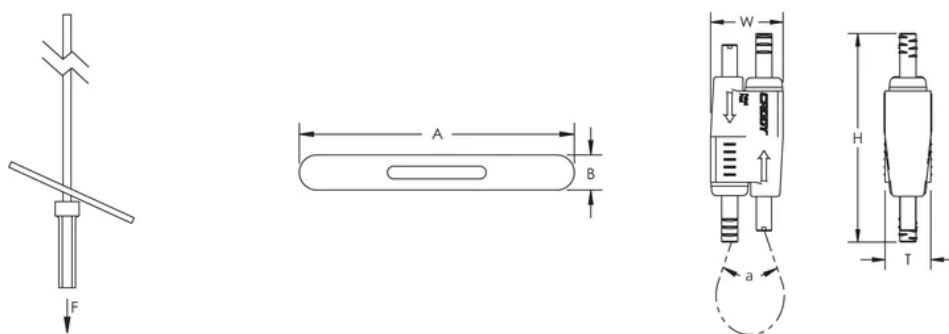

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER