



# NVENT CADDY SPEED LINK SLS WITH DECKING HOOK



## CERTIFICATIONS



## FEATURES

- Complete system includes wire, locking device and pre-assembled decking hook end fitting
- Quickly and easily attaches to hollow metal decking
- Spring-loaded ends snap into decking hole and lock into place
- Innovative design helps protect the wire from sharp edges of decking hole, minimizing risk of damage to wire
- Finger tightening of nut secures the locking device into position without tools
- Installs in strut profiles without the need to insert fingers or tools into the strut

## SPECIFICATIONS

Table 1/2						
Catalog Number	Material	Finish	Static Load Safety Factor	Complies With	Wire Rope Diameter	Wire Rope Length
SLS2L3DH	Steel, Zinc Alloy, Polypropylene	Electrogalvanized	5:1	SMACNA HVAC-DCS	2 mm	9.9'

Table 2/2

Catalog Number	Roof Decking Sheet Thickness	A	Hole Size 1 (HS1)	Static Load (F)
SLS2L3DH	16 ga Max	0.36"	0.32"	60lb

<b>Hole Size 2 (HS2):</b>	0.310" - 0.38"
<b>Slot Size (SS):</b>	0.31" x 0.25" - 0.31" x 0.38"
<b>Width (W):</b>	0.6"
<b>Height 2 (H2):</b>	1.8
<b>Height 1 (H1):</b>	2.1
<b>Thread Size (TS):</b>	M8
<b>Thickness (T):</b>	0.15" Max

## ADDITIONAL PRODUCT DETAILS


The 2 mm locking device is compatible with C-Channel Types E0 and E0L.

Total load per wire on a multi-tier trapeze must not exceed static load.

Load rating is only applicable if the load-bearing capacity of the supporting element (steel decking) is adequate.

Check with deck manufacturer for recommended load capacity.

## DIAGRAMS

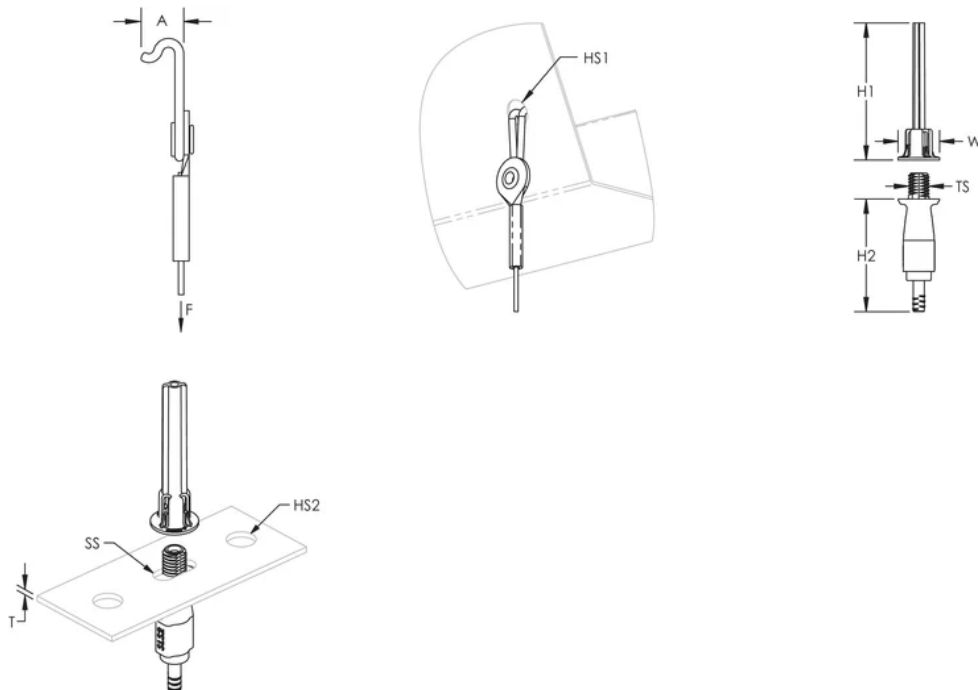

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation,

misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**