




NVENT CADDY SPEED LINK Y-HOOK WITH EYELET EXTENSION

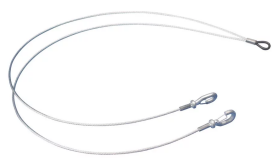

CERTIFICATIONS



FEATURES

- Double hook offers easy attachment to basket tray, cable tray or lighting
- Convenient design allows one hook to be temporarily detached for maintenance or to add cables to the tray
- Y-design provides improved stability
- Spring latch helps provide secure connection

SPECIFICATIONS

- Wire Rope Diameter: 2 mm
- Static Load Safety Factor: 5:1
- Finish: Electrogalvanized
- Material: Steel


Table 1/1						
Catalog Number	Wire Rope "Y" Length (YL)	A	B	C	Static Load (F)	Certifications
SLD2YH500	19.6"	2.3"	0.9"	1/4"	100lb	cUL, ITB, UL

Catalog Number	Wire Rope "Y" Length (YL)	A	B	C	Static Load (F)	Certifications
SLD2YH800	31.4"	2.3"	0.9"	1/4"	100lb	cUL, UL

ADDITIONAL PRODUCT DETAILS

nVent CADDY Speed Link locking device not included.

DIAGRAMS

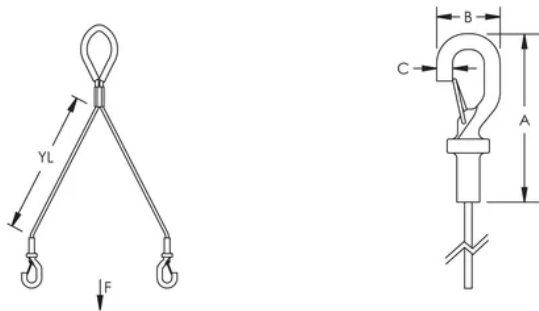

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America +1.800.753.9221 Option 1 – Customer Care Option 2 – Technical Support	Europe Netherlands: +31 800-0200135 France: +33 800 901 793	Europe Germany: 800 1890272 Other Countries: +31 13 5835404	APAC Shanghai: + 86 21 2412 1618/19 Sydney: +61 2 9751 8500
---	--	--	--