

# BRANCH LINE RESTRAINT PIPE ATTACHMENT



## CERTIFICATIONS



## FEATURES

- Accepts 3/8" or 1/2" (M10 or M12) threaded rod
- Quick grip clamp simplifies measuring and cutting of threaded rod
- Eliminates need to cut threaded rod to exact dimensions
- Works with rough-cut threaded rod and eliminates pipe-side deburring
- Can be installed with threaded rod above or below the service pipe
- Shear-off head helps ensure correct torque and simplifies inspection

## SPECIFICATIONS


- Finish:** Electrogalvanized
- Material:** Steel

Table 1/1

Catalog Number	Pipe Size	Outer Diameter (OD)	Rod Size (RS)	Length (L)	Height (H)	Width (W)
CSBRRP0100EG	1in	1.32in	0.375in, 0.5in	1.63in	2.9in	0.88in

Catalog Number	Pipe Size	Outer Diameter (OD)	Rod Size(RS)	Length (L)	Height (H)	Width (W)
CSBBRP0125EG	1.25in	1.66in	0.375in, 0.5in	1.97in	3.25in	0.88in
CSBBRP0150EG	1.5in	1.9in	0.375in, 0.5in	2.21in	3.5in	0.88in
CSBBRP0200EG	2in	2.38in	0.375in, 0.5in	2.69in	3.95in	0.88in

## DIAGRAMS

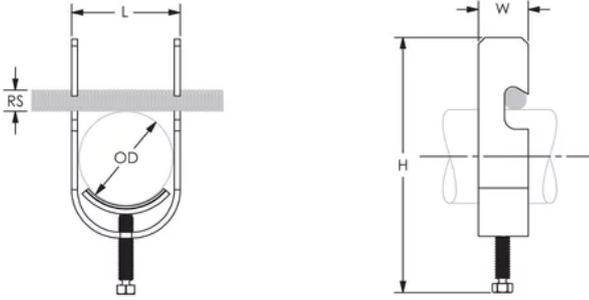

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**