


GRID STRAPS FOR PROLINE FRAMES 3-ROW, 1200MM, GALVANIZED, MILD STEEL

CATALOG NUMBER

PGH3S12

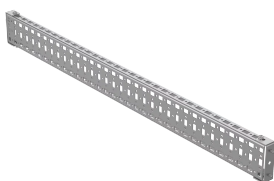

The Grid Straps are provided with specially designed rectangular holes to allow the use of cage nuts or front-loading cage nuts. Mounting holes are provided on 25-mm centers. Grid Straps are available with either 1 row or 3 rows of holes and are furnished in pairs. Mounting hardware to attach Grid Straps to the frame or to other Grid Straps is included.

FEATURES

Can be mounted vertically between horizontally mounted Grid Straps

Can be mounted left-to-right horizontally between front-to-back pairs or from the sides of the ProLine frame

Can be mounted front-to-back horizontally across the bottom or sides of the ProLine frame

When mounting width-wise from vertical to vertical, the grid strap chosen must be 100mm greater than the nominal size (i.e. 800mm wide enclosure would take a 900mm grid strap in this orientation)

Furnished in pairs, and constructed from 14 gauge (1.75mm) conductive steel

PRODUCT ATTRIBUTES

Article Number: 16028

Material: Mild Steel

Hole Pattern: Three Rows

Weight: 8lb

Finish: Galvanized

Thickness: 14ga

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction,

property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER

© 2025 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.