

## TELECOM MAIN GROUNDING BUSBAR



### CERTIFICATIONS



### FEATURES

Meets TIA-607-C and TIA-607-D and conforms to BICSI® recommendations

Complies with NEMA® standards

Accepts two hole lugs with 5/16" or 7/16" bolt holes (hardware not included)

Telecom grounding busbar splice kits are available to extend the length of the busbar

### SPECIFICATIONS

**Thickness (T):** 1/4"  
**Width (W):** 4"  
**Material:** Copper


Table 1/2

| Catalog Number | Tin Plating | Length 1 (L1) | Length 2 (L2) | Hole Size 1 (HS1) | Hole Size 1 Number of Pairs | Hole Size 2 (HS2) |
|----------------|-------------|---------------|---------------|-------------------|-----------------------------|-------------------|
| TMGBA12L15P    | No          | 12"           | 9"            | 5/16"             | 15                          | 7/16"             |
| TMGBA12L15PT   | Yes         | 12"           | 9"            | 5/16"             | 15                          | 7/16"             |
| TMGBA16L19P    | No          | 15 1/2"       | 9"            | 5/16"             | 19                          | 7/16"             |
| TMGBA16L19PT   | Yes         | 15 1/2"       | 9"            | 5/16"             | 19                          | 7/16"             |

| Catalog Number | Tin Plating | Length 1(L1) | Length 2(L2) | Hole Size 1 (HS1) | Hole Size 1 Number of Pairs | Hole Size 2 (HS2) |
|----------------|-------------|--------------|--------------|-------------------|-----------------------------|-------------------|
| TMGBA18L23P    | No          | 17 3/4"      | 9"           | 5/16"             | 23                          | 7/16"             |
| TMGBA18L23PT   | Yes         | 17 3/4"      | 9"           | 5/16"             | 23                          | 7/16"             |
| TMGBA20L27P    | No          | 20"          | 9"           | 5/16"             | 27                          | 7/16"             |
| TMGBA20L27PT   | Yes         | 20"          | 9"           | 5/16"             | 27                          | 7/16"             |
| TMGBA24L33P    | No          | 24"          | 18"          | 5/16"             | 33                          | 7/16"             |
| TMGBA24L33PT   | Yes         | 24"          | 18"          | 5/16"             | 33                          | 7/16"             |
| TMGBA29L41P    | No          | 29"          | 18"          | 5/16"             | 41                          | 7/16"             |
| TMGBA29L41PT   | Yes         | 29"          | 18"          | 5/16"             | 41                          | 7/16"             |

| Table 2/2      |                             |    |        |      |      |
|----------------|-----------------------------|----|--------|------|------|
| Catalog Number | Hole Size 2 Number of Pairs | A  | B      | C    | D    |
| TMGBA12L15P    | 3                           | 1" | 1 1/8" | 5/8" | 5/8" |
| TMGBA12L15PT   | 3                           | 1" | 1 1/8" | 5/8" | 5/8" |
| TMGBA16L19P    | 3                           | 1" | 1 1/8" | 5/8" | 5/8" |
| TMGBA16L19PT   | 3                           | 1" | 1 1/8" | 5/8" | 5/8" |
| TMGBA18L23P    | 3                           | 1" | 1 1/8" | 5/8" | 5/8" |
| TMGBA18L23PT   | 3                           | 1" | 1 1/8" | 5/8" | 5/8" |
| TMGBA20L27P    | 3                           | 1" | 1 1/8" | 5/8" | 5/8" |
| TMGBA20L27PT   | 3                           | 1" | 1 1/8" | 5/8" | 5/8" |
| TMGBA24L33P    | 5                           | 1" | 1 1/8" | 5/8" | 5/8" |
| TMGBA24L33PT   | 5                           | 1" | 1 1/8" | 5/8" | 5/8" |
| TMGBA29L41P    | 5                           | 1" | 1 1/8" | 5/8" | 5/8" |
| TMGBA29L41PT   | 5                           | 1" | 1 1/8" | 5/8" | 5/8" |

## DIAGRAMS

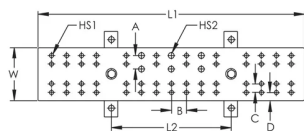

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction,

property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**