


FRONT HANDLE ONE-PIECE, WIDTH 12.2 MM

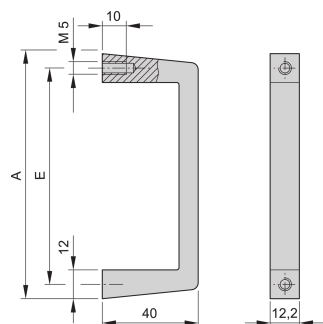

The handle can be assembled to a subrack or 19" front panel. Available with clear or black anodized surface. Handles will be bolted from the rear side.

CERTIFICATIONS



FEATURES

Static load-carrying capacity 30 kg/pair

Bolted from rear

SPECIFICATIONS

Table 1/2

Catalog Number	Product Type	Works With	Handle Type	Rack Height	Material	Color
10501-116	Handle	Subracks	Straight	1U	Aluminum	Silver
10501-004	Handle	Subracks	Straight	2U	Aluminum	Silver
10501-005	Handle	Subracks	Straight	3U	Aluminum	Silver
10501-006	Handle	Subracks	Straight	4U	Aluminum	Silver
10501-007	Handle	Subracks	Straight	5U	Aluminum	Silver
10501-008	Handle	Subracks	Straight	6U	Aluminum	Silver
10501-016	Handle	Subracks	Straight	2U	Aluminum	Silver
10501-018	Handle	Subracks	Straight	4U	Aluminum	Silver

Catalog Number	ProductType	Works With	Handle Type	Rack Height	Material	Color
10501-020	Handle	Subracks	Angled Handle	3U	Aluminum	Silver
10501-021	Handle	Subracks	Angled Handle	4U	Aluminum	Silver
10501-022	Handle	Subracks	Angled Handle	6U	Aluminum	Silver
10501-025	Handle	Subracks	Straight	2U	Aluminum	Black
10501-026	Handle	Subracks	Straight	3U	Aluminum	Black
10501-027	Handle	Subracks	Straight	4U	Aluminum	Black
10501-028	Handle	Subracks	Straight	5U	Aluminum	Black
10501-029	Handle	Subracks	Straight	6U	Aluminum	Black

Table 2/2		
Catalog Number	Package Quantity	Finish
10501-116	1	Anodized
10501-004	1	Anodized
10501-005	1	Anodized
10501-006	1	Anodized
10501-007	1	Anodized
10501-008	1	Anodized
10501-016	1	Anodized
10501-018	1	Anodized
10501-020	1	Anodized
10501-021	1	Anodized
10501-022	1	Anodized
10501-025	1	Anodized
10501-026	1	Anodized
10501-027	1	Anodized
10501-028	1	Anodized
10501-029	1	Anodized

ADDITIONAL PRODUCT DETAILS

Please order assembly part kit separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER