



NVENT CADDY SPEED LINK SLK WITH THREADED STUD END



CERTIFICATIONS



FEATURES

Complete system includes wire, locking device and pre-assembled threaded stud end fitting

Attaches to structures with threaded anchors or devices with threaded hole

Connects directly to threaded devices in trapeze assemblies, light fixtures, HVAC assemblies or signage

SPECIFICATIONS

| | |
|-----------------------------------|--------------------------------|
| Static Load Safety Factor: | 5:1 |
| Finish: | Electrogalvanized |
| Material: | Steel;Polypropylene;Zinc Alloy |
| Complies With: | SMACNA HVAC-DCS |

Table 1/2


| Catalog Number | Article Number | Wire Rope Diameter | Wire Rope Length | Rod Size (RS) | Screw Length (L) | Height (H) |
|----------------|----------------|--------------------|------------------|---------------|------------------|------------|
| SLK2L3SEM8 | 196561 | 2 mm | 3m | 8 | 45mm | 55 mm |
| SLK2L5SEM8 | 196563 | 2 mm | 5m | 8 | 45mm | 55 mm |
| SLK3L2SEM10 | 196718 | 3 mm | 2m | 10 | 45mm | 62 mm |

| Catalog Number | Article Number | Wire Rope Diameter | Wire Rope Length | Rod Size(RS) | ScrewLength (L) | Height (H) |
|----------------|----------------|--------------------|------------------|--------------|-----------------|------------|
| SLK3L3SEM10 | 196719 | 3 mm | 3m | 10 | 45mm | 62 mm |
| SLK3L5SEM10 | 196720 | 3 mm | 5m | 10 | 45mm | 62 mm |

Table 2/2

| Catalog Number | Article Number | Width (W) | Thickness (T) | Angle (a) | Static Load (F) | Certifications |
|----------------|----------------|-----------|---------------|-----------|-----------------|----------------|
| SLK2L3SEM8 | 196561 | 19 mm | 12.5 mm | 90 ° Max | 440N | cUL, UL |
| SLK2L5SEM8 | 196563 | 19 mm | 12.5 mm | 90 ° Max | 440N | cUL, UL |
| SLK3L2SEM10 | 196718 | 24 mm | 16 mm | 90 ° Max | 890N | |
| SLK3L3SEM10 | 196719 | 24 mm | 16 mm | 90 ° Max | 890N | |
| SLK3L5SEM10 | 196720 | 24 mm | 16 mm | 90 ° Max | 890N | |

DIAGRAMS

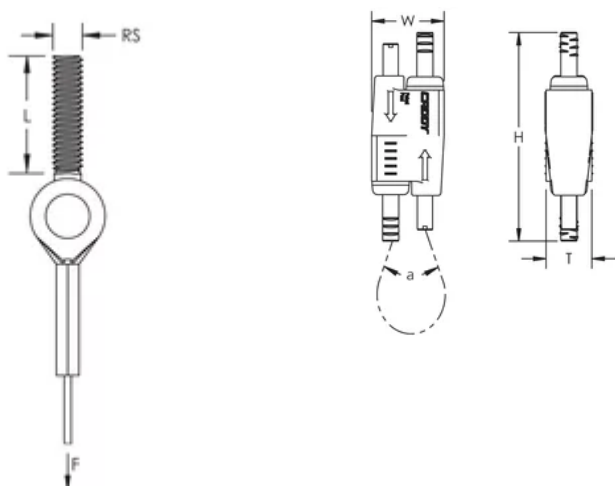

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER