



## NVENT CADDY CUSHION CLAMP INSULATED STRUT CLAMP FOR PIPE/TUBE



### FEATURES

Fits into open side of strut channel

Plastic cushion is hinged to spread apart for easy installation

Reduces noise and absorbs shock by gripping the pipe/tube firmly

Square neck of carriage bolt prevents over-tightening

Nylon locknut prevents loosening under vibration

FM® Specification Tested (from 3/8" to 4" of Copper Tube Size)

### SPECIFICATIONS

**Material:** Steel;Polypropylene

**Finish:** Zinc Chromate

Table 1/2


Catalog Number	Article Number	Outer Diameter (OD)	Copper Tube Size	Pipe Size	NB/DN	Width (W)
CCC0037	598883	9.5 mm	1/4"			39.7 mm
CCC0050	598884	12.7 mm	3/8"	1/4"	8	39.7 mm
CCC0062	598886	15.8 mm	1/2"	3/8"	10	39.7 mm
CCC0087	598891	22.2 mm	3/4"	1/2"	15	39.7 mm
CCC0075	598888	19.1 mm	5/8"			39.7 mm
CCC0100	598892	25.4 mm		3/4"	20	39.7 mm

Catalog Number	Article Number	Outer Diameter (OD)	Copper Tube Size	Pipe Size	NB/DN	Width (W)
CCC0112	598894	28.6 mm	1"			39.7 mm
CCC0125	598895	31.8 mm		1"	25	39.7 mm
CCC0162	598899	41.3 mm	1 1/2"	1 1/4"	32	39.7 mm
CCC0187	598903	47.6 mm		1 1/2"	40	39.7 mm
CCC0212	598906	53.9 mm	2"			39.7 mm
CCC0237	598908	60.3 mm		2"	50	39.7 mm
CCC0450	598957	114.3 mm		4"	100	39.7 mm

Table 2/2

Catalog Number	Article Number	A	B
CCC0037	598883	18.9 mm	35.4 mm
CCC0050	598884	22.1 mm	38.6 mm
CCC0062	598886	25.2 mm	41.7 mm
CCC0087	598891	31.6 mm	48.1 mm
CCC0075	598888	28.4 mm	44.9 mm
CCC0100	598892	34.8 mm	51.3 mm
CCC0112	598894	39 mm	62.4 mm
CCC0125	598895	42.1 mm	65.6 mm
CCC0162	598899	51.6 mm	75.1 mm
CCC0187	598903	59 mm	81.5 mm
CCC0212	598906	68.5 mm	91 mm
CCC0237	598908	74.9 mm	97.4 mm
CCC0450	598957	132 mm	160.5 mm

## DIAGRAMS

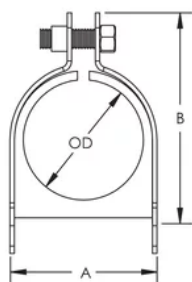

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**