

NVENT CADDY MACROFIX 250 M8/M10



CERTIFICATIONS



FEATURES

Combo head bolt works with slotted, hex, or Phillips drivers

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

SPECIFICATIONS

Table 1/3

Catalog Number	Article Number	Material	Finish	Color	Temperature	Outer Diameter (OD)
MXD280	595992	Steel, EPDM-SBR Rubber	Electrogalvanized	Black	-50 to 110 °C	274 - 280 mm

Table 2/3

Catalog Number	Article Number	Rod Size (RS)	Width (W)	Thickness (T)	Screw Diameter metric (Sc)	Screw Length (L)


MXD280	595992	8, 10	30 mm	3 mm	M8	30mm
--------	--------	-------	-------	------	----	------

Table 3/3		
Catalog Number	Article Number	Static Load (F)
MXD280	595992	2700N

ADDITIONAL PRODUCT DETAILS

Lining is EPDM rubber.

DIAGRAMS

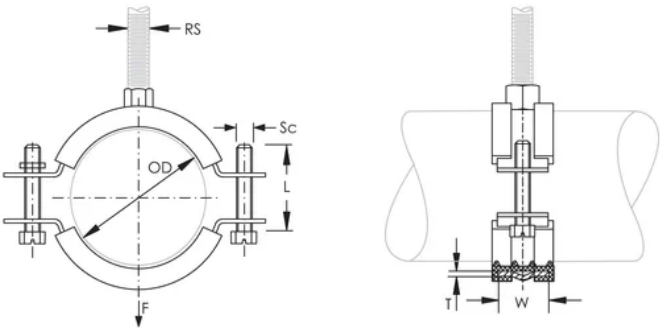

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF**
TRACER