


VARISTAR CP 19" PANEL/SLIDE MOUNT

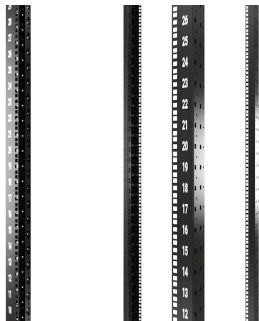

Slide mount with adjustable increments. Assembly in 600 mm wide cabinets directly on the frame. At 800 mm width adapter bracket for reduced width is necessary, for partial-height mounting depth members are necessary.

FEATURES

19" panel/slide mount with U indicator

Depth-adjustable in 25 mm increments

In accordance with IEC 60297-1 (DIN 41 494, Part 1)

SPECIFICATIONS

Table 1/2

Catalog Number	Product Type	Height	Rack Height	Package Quantity	Finish	Material
24630-013	Slide Mount	2000mm	42U	4	Powder Coated	Steel
24630-014	Slide Mount	2200mm	47U	4	Powder Coated	Steel
24630-015	Slide Mount	2450mm	52U	4	Powder Coated	Steel

Table 2/2

Catalog Number	Color	Color Code
24630-013	Jet Black	RAL 9005
24630-014	Jet Black	RAL 9005
24630-015	Jet Black	RAL 9005

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction,

property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER

© 2025 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.