

PX NI HEAVY DUTY PIPE CLAMP WITH EXTERNAL THREAD



FEATURES

Includes male/female combination nut

Heavy duty

SPECIFICATIONS

Finish: Electrogalvanized

Nut Included: Yes

Table 1/3

Catalog Number	Article Number	Material	Outer Diameter (OD)	Pipe Size	Pipe Size Range	NB/DN
PXN025S6	577460	Stainless Steel 316 (EN 1.4401)	21 - 25 mm	1/2"	0.5 in	15
PXN031S6	577470	Stainless Steel 316 (EN 1.4401)	26 - 31 mm	3/4"	0.75 in	20
PXN036S6	577480	Stainless Steel 316 (EN 1.4401)	32 - 36 mm	1"	1 in	25
PXN046S6	577500	Stainless Steel 316 (EN 1.4401)	41 - 46 mm	1 1/4"	1.25 in min	32
PXN052S6	577510	Stainless Steel 316 (EN 1.4401)	47 - 52 mm	1 1/2"	1.5 in	40
PXN063S6	577530	Stainless Steel 316 (EN 1.4401)	59 - 63 mm	2"	2 in min	50

Catalog Number	Article Number	Material	Outer Diameter (OD)	Pipe Size	Pipe Size Range	NB/DN
PXN079S6	577560	Stainless Steel 316 (EN 1.4401)	74 - 79 mm	2 1/2"	2.5 in	65
PXN092S6	577580	Stainless Steel 316 (EN 1.4401)	87 - 92 mm	3"	3 in	80
PXN105S6	577600	Stainless Steel 316 (EN 1.4401)	100 - 105 mm	3 1/2"	3.5 in	
PXN117S6	577620	Stainless Steel 316 (EN 1.4401)	112 - 117 mm	4"	4 in	100
PXN025EG	577060	Steel	21 - 25 mm	1/2"	0.5 in	15
PXN031EG	577070	Steel	26 - 31 mm	3/4"	0.75 in	20
PXN036EG	577080	Steel	32 - 36 mm	1"	1 in	25
PXN046EG	577100	Steel	41 - 46 mm	1 1/4"	1.25 in min	32
PXN052EG	577110	Steel	47 - 52 mm	1 1/2"	1.5 in	40
PXN063EG	577130	Steel	59 - 63 mm	2"	2 in min	50
PXN073EG	577150	Steel	70 - 73 mm			
PXN079EG	577160	Steel	74 - 79 mm	2 1/2"	2.5 in	65
PXN092EG	577180	Steel	87 - 92 mm	3"	3 in	80
PXN117EG	577220	Steel	112 - 117 mm	4"	4 in	100
PXN143S6	577660	Stainless Steel 316 (EN 1.4401)	137 - 143 mm	5"	5 in	125
PXN163S6	577690	Stainless Steel 316 (EN 1.4401)	157 - 163 mm			
PXN169S6	577700	Stainless Steel 316 (EN 1.4401)	164 - 169 mm	6"	6 in	150
PXN175S6	577710	Stainless Steel 316 (EN 1.4401)	170 - 175 mm			
PXN182S6	577720	Stainless Steel 316 (EN 1.4401)	176 - 182 mm			
PXN205S6	577750	Stainless Steel 316 (EN 1.4401)	199 - 205 mm			
PXN219S6	577770	Stainless Steel 316 (EN 1.4401)	213 - 219 mm	8"	8 in	200
PXN252S6	577800	Stainless Steel 316 (EN 1.4401)	246 - 252 mm			
PXN169EG	577300	Steel	164 - 169 mm	6"	6 in	150
PXN252EG	577400	Steel	246 - 252 mm			

Table 2/3


Catalog Number	Article Number	Rod Size (RS)	Gewinde (G)	Width (W)	Thickness (T)	Screw Diameter (Sc)
PXN025S6	577460	10	1/2"	27 mm	2 mm	6
PXN031S6	577470	10	1/2"	27 mm	2 mm	6
PXN036S6	577480	10	1/2"	27 mm	2 mm	6
PXN046S6	577500	10	1/2"	27 mm	2 mm	6
PXN052S6	577510	10	1/2"	27 mm	2 mm	6
PXN063S6	577530	10	1/2"	27 mm	2 mm	6
PXN079S6	577560	10	1/2"	31 mm	2 mm	8
PXN092S6	577580	10	1/2"	31 mm	2 mm	8
PXN105S6	577600	10	1/2"	31 mm	2 mm	8
PXN117S6	577620	10	1/2"	31 mm	2 mm	8
PXN025EG	577060	10	1/2"	27 mm	2.2 mm	6
PXN031EG	577070	10	1/2"	27 mm	2.2 mm	6
PXN036EG	577080	10	1/2"	27 mm	2.2 mm	6
PXN046EG	577100	10	1/2"	27 mm	2.2 mm	6
PXN052EG	577110	10	1/2"	27 mm	2.2 mm	6
PXN063EG	577130	10	1/2"	27 mm	2.2 mm	6
PXN073EG	577150	10	1/2"	27 mm	2.2 mm	6
PXN079EG	577160	10	1/2"	31 mm	2.5 mm	6
PXN092EG	577180	10	1/2"	31 mm	2.5 mm	6
PXN117EG	577220	10	1/2"	31 mm	2.5 mm	6
PXN143S6	577660	12	3/4"	38 mm	2.5 mm	8
PXN163S6	577690	12	3/4"	38 mm	2.5 mm	8
PXN169S6	577700	12	3/4"	38 mm	2.5 mm	8
PXN175S6	577710	12	3/4"	38 mm	2.5 mm	8
PXN182S6	577720	12	3/4"	38 mm	2.5 mm	8
PXN205S6	577750	12	3/4"	38 mm	2.5 mm	8
PXN219S6	577770	12	3/4"	38 mm	2.5 mm	8
PXN252S6	577800	12	3/4"	38 mm	2.5 mm	8
PXN169EG	577300	12	3/4"	38 mm	2.9 mm	8
PXN252EG	577400	12	3/4"	38 mm	2.9 mm	8

Table 3/3

Catalog Number	Article Number	Screw Length (L)	Static Load (F)
----------------	----------------	------------------	-----------------

PXN025S6	577460	20mm	2500N
PXN031S6	577470	20mm	2500N
PXN036S6	577480	20mm	2500N
PXN046S6	577500	20mm	2500N
PXN052S6	577510	20mm	2500N
PXN063S6	577530	20mm	2500N
PXN079S6	577560	25mm	2500N
PXN092S6	577580	25mm	2500N
PXN105S6	577600	25mm	2500N
PXN117S6	577620	25mm	2500N
PXN025EG	577060	20mm	2500N
PXN031EG	577070	20mm	2500N
PXN036EG	577080	20mm	2500N
PXN046EG	577100	20mm	2500N
PXN052EG	577110	25mm	2500N
PXN063EG	577130	25mm	2500N
PXN073EG	577150	25mm	2500N
PXN079EG	577160	25mm	2500N
PXN092EG	577180	25mm	2500N
PXN117EG	577220	25mm	2500N
PXN143S6	577660	30mm	3500N
PXN163S6	577690	30mm	3500N
PXN169S6	577700	30mm	3500N
PXN175S6	577710	30mm	3500N
PXN182S6	577720	30mm	3500N
PXN205S6	577750	30mm	3500N
PXN219S6	577770	30mm	3500N
PXN252S6	577800	30mm	3500N
PXN169EG	577300	30mm	3500N
PXN252EG	577400	30mm	3500N

DIAGRAMS

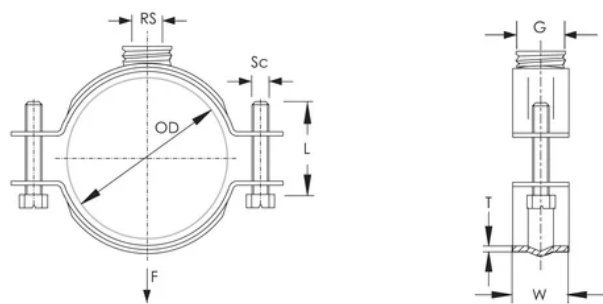

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER