


STATIC HANDLE ALU-PROFILE IN TRAPEZOID FORM

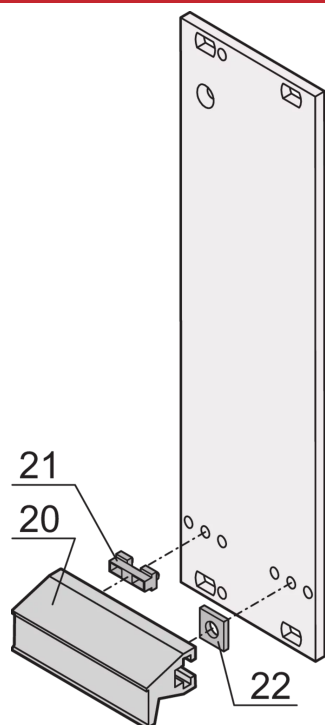

The static Alu-profile handle, trapezoid form can be mounted to a front panel for extraction of the PCB.

CERTIFICATIONS



FEATURES

Aluminium profile handle

SPECIFICATIONS

Table 1/2

Catalog Number	Product Type	Type	Works With	Handle Type	Rack Width	Width (W)
20809-281	Handle	Static	Front Panels	Aluminum Profile	3HP	13.8mm

Catalog Number	ProductType	Type	Works With	Handle Type	Rack Width	Width (W)
20809-282	Handle	Static	Front Panels	Aluminum Profile	4HP	18.9mm
20809-283	Handle	Static	Front Panels	Aluminum Profile	5HP	24mm
20809-284	Handle	Static	Front Panels	Aluminum Profile	6HP	29mm
20809-285	Handle	Static	Front Panels	Aluminum Profile	7HP	34.1mm
20809-286	Handle	Static	Front Panels	Aluminum Profile	8HP	39.2mm
20809-287	Handle	Static	Front Panels	Aluminum Profile	9HP	44.3mm
20809-288	Handle	Static	Front Panels	Aluminum Profile	10HP	49.4mm
20809-289	Handle	Static	Front Panels	Aluminum Profile	12HP	59.6mm
20809-290	Handle	Static	Front Panels	Aluminum Profile	14HP	69.7mm
20809-291	Handle	Static	Front Panels	Aluminum Profile	21HP	105.2mm
20809-292	Handle	Static	Front Panels	Aluminum Profile	28HP	140.8mm
20809-293	Handle	Static	Front Panels	Aluminum Profile	42HP	212mm
30809-428	Handle	Static	Front Panels	Aluminum Profile		1000mm


Table 2/2				
Catalog Number	Material	Color	Package Quantity	Finish
20809-281	Aluminum	Silver	1	Anodized
20809-282	Aluminum	Silver	1	Anodized
20809-283	Aluminum	Silver	1	Anodized
20809-284	Aluminum	Silver	1	Anodized
20809-285	Aluminum	Silver	1	Anodized
20809-286	Aluminum	Silver	1	Anodized
20809-287	Aluminum	Silver	1	Anodized
20809-288	Aluminum	Silver	1	Anodized
20809-289	Aluminum	Silver	1	Anodized
20809-290	Aluminum	Silver	1	Anodized

Catalog Number	Material	Color	Package Quantity	Finish
20809-291	Aluminum	Silver	1	Anodized
20809-292	Aluminum	Silver	1	Anodized
20809-293	Aluminum	Silver	1	Anodized
30809-428	Aluminum	Silver	1	Anodized

ADDITIONAL PRODUCT DETAILS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMS

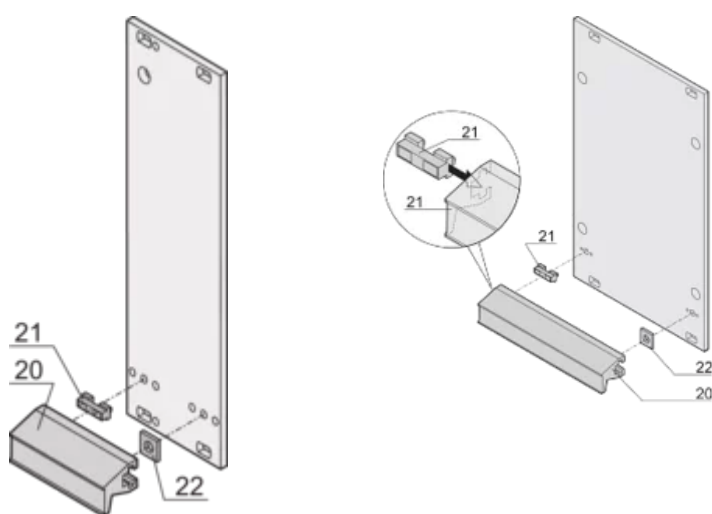

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations

+1.763.422.2661

Chat with us:

schroff.nvent.com

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

schroff.nvent.com

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

schroff.nvent.com



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER