


FRONT PANEL ALTERNATIVE FOR COMBINED MOUNTING

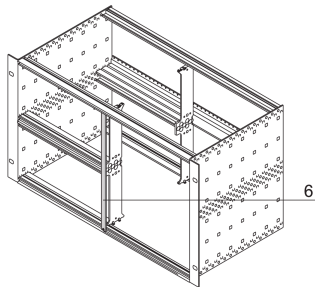

The 2 HP wide front panel covers an open slot. The U-profile front panel can be combined with a textile EMC gasket. It be fixed with screws and washers. Due to the 2 HP width no sleeves can be used.

CERTIFICATIONS



CARACTERÍSTICAS

U-profile front panel 6 U, 2 HP, Al, 2.5 mm

Prepared for textile EMC gasket

ESPECIFICACIONES

Table 1/2

Número de catálogo	Treated Edges	Front Finish	Rear Finish	Package Quantity	Product Type	Product Family
30849-140	No	Anodizado	Conductive	5	Front Panel	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO

Table 2/2

Número de catálogo	Works With	Rack Height
30849-140	Subracks, Cases	6 U

ADDITIONAL PRODUCT DETAILS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Las hojas de instrucciones están disponibles en www.nvent.com y con su representante de atención al cliente de nVent. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER