


MULTIPACPRO 19" CHASSIS BASIC KIT

Such a kit enables a customer to configure the 3 different top / bottom covers.

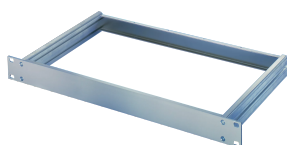

CERTIFICATIONS



CARACTERÍSTICAS

For non-standardized assemblies (1 ... 5 U) and standardized assemblies (1, 2 U) conforming to IEC 60297-3-105

Frame consists of two lateral parts and front/rear panel

Material: aluminium

Select further components (Accessories)

ESPECIFICACIONES

Table 1/2

Número de catálogo	Usable Width	EMC Shielding	Product Type	Product Family	Tipo	Rack Height
20860-201	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	1 U
20860-202	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	1 U
20860-203	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	1 U
20860-210	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	2 U

Número de catálogo	UsableWidth	EMC Shielding	ProductType	Product Family	Tipo	Rack Height
20860-211	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	2 U
20860-212	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	2 U
20860-219	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	3 U
20860-220	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	3 U
20860-221	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	3 U
20860-222	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	3 U
20860-228	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	4 U
20860-229	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	4 U
20860-230	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	4 U
20860-231	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	4 U
20860-240	403 mm	No (Retrofittable)	Subrack/Chassis	MultipacPRO	Configurable	5 U

Table 2/2			
Número de catálogo	Cumple con	Montaje	Profundidad
20860-201	IEC 60297-3-100	Rack	220 mm
20860-202	IEC 60297-3-100	Rack	280 mm
20860-203	IEC 60297-3-100	Rack	340 mm
20860-210	IEC 60297-3-100	Rack	220 mm
20860-211	IEC 60297-3-100	Rack	280 mm
20860-212	IEC 60297-3-100	Rack	340 mm
20860-219	IEC 60297-3-100	Rack	280 mm
20860-220	IEC 60297-3-100	Rack	340 mm
20860-221	IEC 60297-3-100	Rack	400 mm
20860-222	IEC 60297-3-100	Rack	460 mm
20860-228	IEC 60297-3-100	Rack	280 mm
20860-229	IEC 60297-3-100	Rack	340 mm
20860-230	IEC 60297-3-100	Rack	400 mm

Número de catálogo	Cumple con	Montaje	Profundidad
20860-231	IEC 60297-3-100	Rack	460 mm
20860-240	IEC 60297-3-100	Rack	460 mm

ADDITIONAL PRODUCT DETAILS

Please order mounting plate, cover and base plates, handles, telescopic slides separately.

Dimensions h = clear mounting height = H-8.1 mm, b = clear mounting width = 403 mm.

ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Las hojas de instrucciones están disponibles en www.nvent.com y con su representante de atención al cliente de nVent. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER