


STATIC HANDLE ALU-PROFILE IN TRAPEZOID FORM

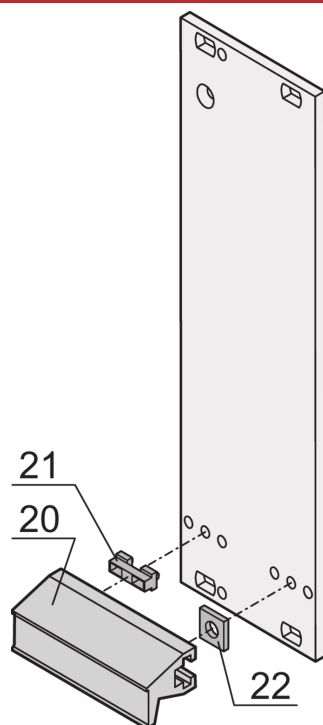

The static Alu-profile handle, trapezoid form can be mounted to a front panel for extraction of the PCB.

CERTIFICATIONS



FEATURES

Aluminium profile handle

SPECIFICATIONS

Table 1/2

Número de catálogo	Tipo de producto	Tipo	Funciona con	Tipo de manija	Ancho de rack	Ancho (W)
20809-281	Handle	Static	Front Panels	Aluminum Profile	3HP	13.8mm

Número de catálogo	Tipo de producto	Tipo	Funcionacon	Tipo de manija	Ancho de rack	Ancho (W)
20809-282	Handle	Static	Front Panels	Aluminum Profile	4HP	18.9mm
20809-283	Handle	Static	Front Panels	Aluminum Profile	5HP	24mm
20809-284	Handle	Static	Front Panels	Aluminum Profile	6HP	29mm
20809-285	Handle	Static	Front Panels	Aluminum Profile	7HP	34.1mm
20809-286	Handle	Static	Front Panels	Aluminum Profile	8HP	39.2mm
20809-287	Handle	Static	Front Panels	Aluminum Profile	9HP	44.3mm
20809-288	Handle	Static	Front Panels	Aluminum Profile	10HP	49.4mm
20809-289	Handle	Static	Front Panels	Aluminum Profile	12HP	59.6mm
20809-290	Handle	Static	Front Panels	Aluminum Profile	14HP	69.7mm
20809-291	Handle	Static	Front Panels	Aluminum Profile	21HP	105.2mm
20809-292	Handle	Static	Front Panels	Aluminum Profile	28HP	140.8mm
20809-293	Handle	Static	Front Panels	Aluminum Profile	42HP	212mm
30809-428	Handle	Static	Front Panels	Aluminum Profile		1000mm


Table 2/2				
Número de catálogo	Material	Color	Cantidad de paquetes	Acabado
20809-281	Aluminum	Silver	1	Anodized
20809-282	Aluminum	Silver	1	Anodized
20809-283	Aluminum	Silver	1	Anodized
20809-284	Aluminum	Silver	1	Anodized
20809-285	Aluminum	Silver	1	Anodized
20809-286	Aluminum	Silver	1	Anodized
20809-287	Aluminum	Silver	1	Anodized
20809-288	Aluminum	Silver	1	Anodized
20809-289	Aluminum	Silver	1	Anodized

Número de catálogo	Material	Color	Cantidad de paquetes	Acabado
20809-290	Aluminum	Silver	1	Anodized
20809-291	Aluminum	Silver	1	Anodized
20809-292	Aluminum	Silver	1	Anodized
20809-293	Aluminum	Silver	1	Anodized
30809-428	Aluminum	Silver	1	Anodized

ADDITIONAL PRODUCT DETAILS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMS

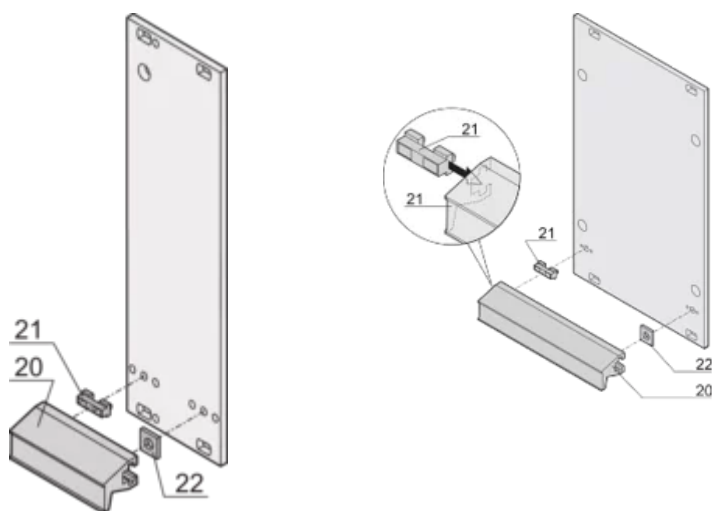

ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.

North America

All locations

+1.763.422.2661

Chat with us:

schroff.nvent.com

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

schroff.nvent.com

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

schroff.nvent.com



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER