

19" FRONT PANEL



Front panels are Al anodized, colours light grey (RAL 7035) or black grey (RAL 7021).

CERTIFICATIONS



FEATURES

Al anodized, 3 mm

SPECIFICATIONS

Accessory Type: Front panel

Table 1/3

Número de catálogo	Tipo	Montaje	Front Finish	Rear Finish	Treated Edges	EMC Shielding
30118-299	19" Front Panel	Screw-on Front	Pintado	Pintado		No
30118-948	19" Front Panel	Screw-on Front	Pintado	Pintado		No
30219-098	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
40304-074	19" Front Panel	Screw-on Front	Anodized	Anodized	Sí	No
30118-301	19" Front Panel	Screw-on Front	Pintado	Pintado		No
30118-302	19" Front Panel	Screw-on Front	Pintado	Pintado		No
30118-303	19" Front Panel	Screw-on Front	Pintado	Pintado		No

Número de catálogo	Tipo	Montaje	Front Finish	Rear Finish	Treated Edges	EMC Shielding
30118-304	19" Front Panel	Screw-on Front	Pintado	Pintado		No
30118-305	19" Front Panel	Screw-on Front	Pintado	Pintado		No
30118-306	19" Front Panel	Screw-on Front	Pintado	Pintado		No
30118-307	19" Front Panel	Screw-on Front	Pintado	Pintado		No
30118-308	19" Front Panel	Screw-on Front	Pintado	Pintado		No
30118-309	19" Front Panel	Screw-on Front	Pintado	Pintado		No
30118-949	19" Front Panel	Screw-on Front	Pintado	Pintado		No
30118-950	19" Front Panel	Screw-on Front	Pintado	Pintado		No
30118-951	19" Front Panel	Screw-on Front	Pintado	Pintado		No
30118-952	19" Front Panel	Screw-on Front	Pintado	Pintado		No
30118-953	19" Front Panel	Screw-on Front	Pintado	Pintado		No
30118-954	19" Front Panel	Screw-on Front	Pintado	Pintado		No
30118-955	19" Front Panel	Screw-on Front	Pintado	Pintado		No
30118-956	19" Front Panel	Screw-on Front	Pintado	Pintado		No
30118-957	19" Front Panel	Screw-on Front	Pintado	Pintado		No
30219-101	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
30219-104	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
30219-107	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
30219-110	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
30219-113	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
30219-137	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
30219-138	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
30219-143	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
30219-144	19" Front Panel	Screw-on Front	Anodized	Anodized	No	No
40304-075	19" Front Panel	Screw-on Front	Anodized	Anodized	Sí	No
40304-076	19" Front Panel	Screw-on Front	Anodized	Anodized	Sí	No
40304-077	19" Front Panel	Screw-on Front	Anodized	Anodized	Sí	No
40304-078	19" Front Panel	Screw-on Front	Anodized	Anodized	Sí	No
40304-079	19" Front Panel	Screw-on Front	Anodized	Anodized	Sí	No
40304-080	19" Front Panel	Screw-on Front	Anodized	Anodized	Sí	No
40304-081	19" Front Panel	Screw-on Front	Anodized	Anodized	Sí	No
40304-082	19" Front Panel	Screw-on Front	Anodized	Anodized	Sí	No
40304-083	19" Front Panel	Screw-on Front	Anodized	Anodized	Sí	No

Table 2/3

Número de catálogo	Ancho de rack	Tipo de producto	Altura (H)	Funciona con	Altura del rack	Cantidad de paquetes
30118-299	95HP	Front Panel	43.6mm	Cabinet, Wallmount Cases, 19" cases	1U	1
30118-948	95HP	Front Panel	43.6mm	Cabinet, Wallmount Cases, 19" cases	1U	1
30219-098	95HP	Front Panel	43.6mm	Cabinet, Wallmount Cases, 19" cases	1U	1
40304-074	95HP	Front Panel	43.6mm	Cabinet, Wallmount Cases, 19" cases	1U	1
30118-301	95HP	Front Panel	88.1mm	Cabinet, Wallmount Cases, 19" cases	2U	1
30118-302	95HP	Front Panel	132.5mm	Cabinet, Wallmount Cases, 19" cases	3U	1
30118-303	95HP	Front Panel	177mm	Cabinet, Wallmount Cases, 19" cases	4U	1
30118-304	95HP	Front Panel	221.4mm	Cabinet, Wallmount Cases, 19" cases	5U	1
30118-305	95HP	Front Panel	265.9mm	Cabinet, Wallmount Cases, 19" cases	6U	1
30118-306	95HP	Front Panel	310.3mm	Cabinet, Wallmount Cases, 19" cases	7U	1
30118-307	95HP	Front Panel	354.8mm	Cabinet, Wallmount Cases, 19" cases	8U	1

Número de catálogo	Ancho de rack	Tipo de producto	Altura (H)	Funcionacon	Altura del rack	Cantidad de paquetes
30118-308	95HP	Front Panel	399.2mm	Cabinet, Wallmount Cases, 19" cases	9U	1
30118-309	95HP	Front Panel	443.7mm	Cabinet, Wallmount Cases, 19" cases	10U	1
30118-949	95HP	Front Panel	88.1mm	Cabinet, Wallmount Cases, 19" cases	2U	1
30118-950	95HP	Front Panel	132.5mm	Cabinet, Wallmount Cases, 19" cases	3U	1
30118-951	95HP	Front Panel	177mm	Cabinet, Wallmount Cases, 19" cases	4U	1
30118-952	95HP	Front Panel	221.4mm	Cabinet, Wallmount Cases, 19" cases	5U	1
30118-953	95HP	Front Panel	265.9mm	Cabinet, Wallmount Cases, 19" cases	6U	1
30118-954	95HP	Front Panel	310.3mm	Cabinet, Wallmount Cases, 19" cases	7U	1
30118-955	95HP	Front Panel	354.8mm	Cabinet, Wallmount Cases, 19" cases	8U	1
30118-956	95HP	Front Panel	399.2mm	Cabinet, Wallmount Cases, 19" cases	9U	1
30118-957	95HP	Front Panel	443.7mm	Cabinet, Wallmount Cases, 19" cases	10U	1

Número de catálogo	Ancho de rack	Tipo de producto	Altura (H)	Funcionacon	Altura del rack	Cantidad de paquetes
30219-101	95HP	Front Panel	88.1mm	Cabinet, Wallmount Cases, 19" cases	2U	1
30219-104	95HP	Front Panel	132.5mm	Cabinet, Wallmount Cases, 19" cases	3U	1
30219-107	95HP	Front Panel	177mm	Cabinet, Wallmount Cases, 19" cases	4U	1
30219-110	95HP	Front Panel	221.4mm	Cabinet, Wallmount Cases, 19" cases	5U	1
30219-113	95HP	Front Panel	265.9mm	Cabinet, Wallmount Cases, 19" cases	6U	1
30219-137	95HP	Front Panel	310.3mm	Cabinet, Wallmount Cases, 19" cases	7U	1
30219-138	95HP	Front Panel	354.8mm	Cabinet, Wallmount Cases, 19" cases	8U	1
30219-143	95HP	Front Panel	399.2mm	Cabinet, Wallmount Cases, 19" cases	9U	1
30219-144	95HP	Front Panel	443.7mm	Cabinet, Wallmount Cases, 19" cases	10U	1
40304-075	95HP	Front Panel	88.1mm	Cabinet, Wallmount Cases, 19" cases	2U	1
40304-076	95HP	Front Panel	132.5mm	Cabinet, Wallmount Cases, 19" cases	3U	1

Número de catálogo	Ancho de rack	Tipo de producto	Altura (H)	Funcionacon	Altura del rack	Cantidad de paquetes
40304-077	95HP	Front Panel	177mm	Cabinet, Wallmount Cases, 19" cases	4U	1
40304-078	95HP	Front Panel	221.4mm	Cabinet, Wallmount Cases, 19" cases	5U	1
40304-079	95HP	Front Panel	265.9mm	Cabinet, Wallmount Cases, 19" cases	6U	1
40304-080	95HP	Front Panel	310.3mm	Cabinet, Wallmount Cases, 19" cases	7U	1
40304-081	95HP	Front Panel	354.8mm	Cabinet, Wallmount Cases, 19" cases	8U	1
40304-082	95HP	Front Panel	399.2mm	Cabinet, Wallmount Cases, 19" cases	9U	1
40304-083	95HP	Front Panel	443.7mm	Cabinet, Wallmount Cases, 19" cases	10U	1


Table 3/3						
Número de catálogo	Acabado	Material	Color	Código de colores	Ancho (W)	Profundidad (D)
30118-299	Powder Coated	Aluminio	Gris Claro	RAL 7035	483mm	3mm
30118-948	Powder Coated	Aluminio	Black Grey	RAL 7021	483mm	3mm
30219-098	Anodized	Aluminio			483mm	3mm
40304-074	Anodized	Aluminio			483mm	4mm
30118-301	Powder Coated	Aluminio	Gris Claro	RAL 7035	483mm	3mm
30118-302	Powder Coated	Aluminio	Gris Claro	RAL 7035	483mm	3mm
30118-303	Powder Coated	Aluminio	Gris Claro	RAL 7035	483mm	3mm
30118-304	Powder Coated	Aluminio	Gris Claro	RAL 7035	483mm	3mm
30118-305	Powder Coated	Aluminio	Gris Claro	RAL 7035	483mm	3mm
30118-306	Powder Coated	Aluminio	Gris Claro	RAL 7035	483mm	3mm

Número de catálogo	Acabado	Material	Color	Código de colores	Ancho (W)	Profundidad (D)
30118-307	Powder Coated	Aluminio	Gris Claro	RAL 7035	483mm	3mm
30118-308	Powder Coated	Aluminio	Gris Claro	RAL 7035	483mm	3mm
30118-309	Powder Coated	Aluminio	Gris Claro	RAL 7035	483mm	3mm
30118-949	Powder Coated	Aluminio	Black Grey	RAL 7021	483mm	3mm
30118-950	Powder Coated	Aluminio	Black Grey	RAL 7021	483mm	3mm
30118-951	Powder Coated	Aluminio	Black Grey	RAL 7021	483mm	3mm
30118-952	Powder Coated	Aluminio	Black Grey	RAL 7021	483mm	3mm
30118-953	Powder Coated	Aluminio	Black Grey	RAL 7021	483mm	3mm
30118-954	Powder Coated	Aluminio	Black Grey	RAL 7021	483mm	3mm
30118-955	Powder Coated	Aluminio	Black Grey	RAL 7021	483mm	3mm
30118-956	Powder Coated	Aluminio	Black Grey	RAL 7021	483mm	3mm
30118-957	Powder Coated	Aluminio	Black Grey	RAL 7021	483mm	3mm
30219-101	Anodized	Aluminio			483mm	3mm
30219-104	Anodized	Aluminio			483mm	3mm
30219-107	Anodized	Aluminio			483mm	3mm
30219-110	Powder Coated	Aluminio			483mm	3mm
30219-113	Anodized	Aluminio			483mm	3mm
30219-137	Anodized	Aluminio			483mm	3mm
30219-138	Anodized	Aluminio			483mm	3mm
30219-143	Anodized	Aluminio			483mm	3mm
30219-144	Anodized	Aluminio			483mm	3mm
40304-075	Anodized	Aluminio			483mm	4mm
40304-076	Anodized	Aluminio			483mm	4mm
40304-077	Anodized	Aluminio			483mm	4mm
40304-078	Anodized	Aluminio			483mm	4mm
40304-079	Anodized	Aluminio			483mm	4mm
40304-080	Anodized	Aluminio			483mm	4mm
40304-081	Anodized	Aluminio			483mm	4mm
40304-082	Anodized	Aluminio			483mm	4mm
40304-083	Anodized	Aluminio			483mm	4mm

ADDITIONAL PRODUCT DETAILS

Please order 19" assembly kit separately.

DIAGRAMS

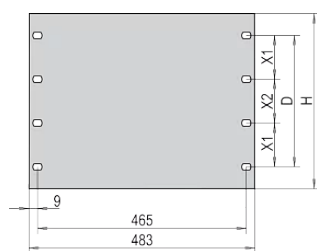

ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER