


## FRONT PANEL, FLAT, REFROFIT SHIELDING, D-SUB CUTOUTS

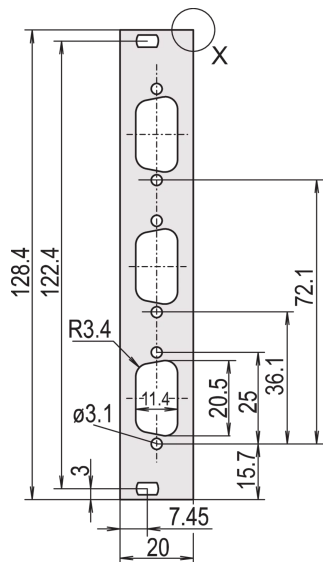

Flat front panel with cutout for D-Sub connectors. Shieldable for stainless steel EMC gasket.

## CERTIFICATIONS



## CARACTERÍSTICAS

For stainless steel EMC gasket

Aluminum, 2.5 mm, front anodized, conductive

## ESPECIFICACIONES

| Table 1/3          |                  |               |              |             |                    |            |
|--------------------|------------------|---------------|--------------|-------------|--------------------|------------|
| Número de catálogo | EMC Gasket Type  | Treated Edges | Front Finish | Rear Finish | EMC Shielding      | Rack Width |
| 30118-348          | Acero inoxidable | No            | Anodizado    | Conductive  | No (Retrofittable) | 4 HP       |
| 30118-349          | Acero inoxidable | No            | Anodizado    | Conductive  | No (Retrofittable) | 4 HP       |

| Número de catálogo | EMC Gasket Type  | Treated Edges | Front Finish | Rear Finish | EMC Shielding      | Rack Width |
|--------------------|------------------|---------------|--------------|-------------|--------------------|------------|
| 30118-350          | Acero inoxidable | No            | Anodizado    | Conductive  | No (Retrofittable) | 4 HP       |
| 30118-351          | Acero inoxidable | No            | Anodizado    | Conductive  | No (Retrofittable) | 4 HP       |
| 30118-352          | Acero inoxidable | No            | Anodizado    | Conductive  | No (Retrofittable) | 4 HP       |
| 30118-353          | Acero inoxidable | No            | Anodizado    | Conductive  | No (Retrofittable) | 4 HP       |
| 30118-354          | Acero inoxidable | No            | Anodizado    | Conductive  | No (Retrofittable) | 4 HP       |

| Table 2/3          |                  |          |              |                            |             |       |
|--------------------|------------------|----------|--------------|----------------------------|-------------|-------|
| Número de catálogo | Package Quantity | Altura   | Product Type | Tipo                       | Rack Height | Ancho |
| 30118-348          | 5                | 128.4 mm | Front Panel  | Front Panel without Handle | 3 U         | 20 mm |
| 30118-349          | 5                | 128.4 mm | Front Panel  | Front Panel without Handle | 3 U         | 20 mm |
| 30118-350          | 5                | 128.4 mm | Front Panel  | Front Panel without Handle | 3 U         | 20 mm |
| 30118-351          | 5                | 128.4 mm | Front Panel  | Front Panel without Handle | 3 U         | 20 mm |
| 30118-352          | 5                | 128.4 mm | Front Panel  | Front Panel without Handle | 3 U         | 20 mm |
| 30118-353          | 5                | 128.4 mm | Front Panel  | Front Panel without Handle | 3 U         | 20 mm |
| 30118-354          | 5                | 128.4 mm | Front Panel  | Front Panel without Handle | 3 U         | 20 mm |

| Table 3/3          |                                 |                |          |
|--------------------|---------------------------------|----------------|----------|
| Número de catálogo | Cumple con                      | Montaje        | Material |
| 30118-348          | IEC 60297-3-101, IEEE 1101.1/10 | Screw-on Front | Aluminio |
| 30118-349          | IEC 60297-3-101, IEEE 1101.1/10 | Screw-on Front | Aluminio |
| 30118-350          | IEC 60297-3-101, IEEE 1101.1/10 | Screw-on Front | Aluminio |
| 30118-351          | IEC 60297-3-101, IEEE 1101.1/10 | Screw-on Front | Aluminio |
| 30118-352          | IEC 60297-3-101, IEEE 1101.1/10 | Screw-on Front | Aluminio |

| Número de catálogo | Cumple con                      | Montaje        | Material |
|--------------------|---------------------------------|----------------|----------|
| 30118-353          | IEC 60297-3-101, IEEE 1101.1/10 | Screw-on Front | Aluminio |
| 30118-354          | IEC 60297-3-101, IEEE 1101.1/10 | Screw-on Front | Aluminio |

## ADDITIONAL PRODUCT DETAILS

Please order fixing material (sleeves, collar screws) separately.

Delivery is in standard pack multiples. Pricing is per individual item.

Please order stainless steel EMC gasket separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Las hojas de instrucciones están disponibles en [www.nvent.com](http://www.nvent.com) y con su representante de atención al cliente de nVent. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**