


## GUIDE RAIL WITH CODING FOR COMPACTPCI/ VME64X, PC

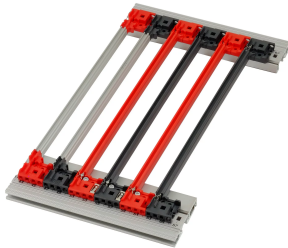

New generation of Wih Coding type guide rails for PCBs or plug-in units. Forms a reliable interface between the subrack mechanics and the sub-assemblies. With the optimized design and the new high quality plastic material not just the stability was significantly increased, but also the fire safety properties improved. Which means the material ensures a low flammability, low smoke toxicity and density and fulfills the EN 45545-2 (Fire Safety in Railway Vehicle) requirements sets R22, R23 and R24 with the

### CERTIFICATIONS



### FEATURES

NEW generation with coding type plastic guide rails for reliable retention of PCBs or plug-in units

Significantly increased stability, due to a optimized design and high quality material (PC)

Improved fire safety properties, fulfills EN 45545-2 requirement sets R22, R23 and R24 with HL3

"Halogen-Free", according to IEC 61249-2-21

Can be clipped into horizontal rails (Al extrusion) or into 1.5 mm thick plates

Can be bolted to the horizontal rails Type H and R for higher shock and vibration requirements

Optional ESD clip for an conductive contact between PCB and horizontal rail available

Storage temperature: from -40 °C ... 130 °C

### SPECIFICATIONS

Table 1/2

| Número de catálogo | Tipo   | Funciona con                                   | Board Depth | Material                    | Color | Cantidad de paquetes |
|--------------------|--------|------------------------------------------------|-------------|-----------------------------|-------|----------------------|
| 64568-085          | Coding | Subracks,<br>Cases, 19"<br>Chassis,<br>Systems | 70mm        | Fiber-Reinforced<br>Plastic | Red   | 1                    |

| Número de catálogo | Tipo   | Funcionacon                           | Board Depth | Material                           | Color        | Cantidad de paquetes |
|--------------------|--------|---------------------------------------|-------------|------------------------------------|--------------|----------------------|
| 64568-086          | Coding | Subracks, Cases, 19" Chassis, Systems | 70mm        | Fiber-Reinforced Plastic           | Grey         | 1                    |
| 64568-091          | Coding | Subracks, Cases, 19" Chassis, Systems | 220mm       | Fiber-Reinforced Plastic           | Red          | 1                    |
| 64568-092          | Coding | Subracks, Cases, 19" Chassis, Systems | 220mm       | Fiber-Reinforced Plastic           | Grey         | 1                    |
| 64568-111          | Coding | Subracks, Cases, 19" Chassis, Systems | 220mm       | Fiber-Reinforced Plastic, Aluminum | Red, Silver  | 1                    |
| 64568-109          | Coding | Subracks, Cases, 19" Chassis, Systems | 160mm       | Fiber-Reinforced Plastic, Aluminum | Red, Silver  | 1                    |
| 64568-110          | Coding | Subracks, Cases, 19" Chassis, Systems | 160mm       | Fiber-Reinforced Plastic, Aluminum | Grey, Silver | 1                    |
| 64568-112          | Coding | Subracks, Cases, 19" Chassis, Systems | 220mm       | Fiber-Reinforced Plastic, Aluminum | Grey, Silver | 1                    |
| 24568-356          | Coding | Subracks, Cases, 19" Chassis, Systems | 160mm       | Fiber-Reinforced Plastic           | Red          | 10                   |
| 24568-357          | Coding | Subracks, Cases, 19" Chassis, Systems | 70mm        | Fiber-Reinforced Plastic           | Red          | 10                   |
| 24568-358          | Coding | Subracks, Cases, 19" Chassis, Systems | 160mm       | Fiber-Reinforced Plastic           | Grey         | 10                   |
| 24568-360          | Coding | Subracks, Cases, 19" Chassis, Systems | 70mm        | Fiber-Reinforced Plastic           | Grey         | 10                   |

Table 2/2

| Número de catálogo | Cumple con | Ancho de la ranura |
|--------------------|------------|--------------------|
| 64568-085          | EN 45545-2 | 2                  |
| 64568-086          | EN 45545-2 | 2                  |
| 64568-091          | EN 45545-2 | 2                  |
| 64568-092          | EN 45545-2 | 2                  |
| 64568-111          | EN 45545-2 | 2.5                |
| 64568-109          | EN 45545-2 | 2.5                |
| 64568-110          | EN 45545-2 | 2.5                |
| 64568-112          | EN 45545-2 | 2.5                |
| 24568-356          | EN 45545-2 | 2                  |
| 24568-357          | EN 45545-2 | 2                  |
| 24568-358          | EN 45545-2 | 2                  |
| 24568-360          | EN 45545-2 | 2                  |

## ADDITIONAL PRODUCT DETAILS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## ADVERTENCIA

Los productos nVent deben instalarse y usarse solo como se indica en las hojas de instrucciones y materiales de capacitación del producto nVent. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. La instalación incorrecta, el mal uso, la aplicación incorrecta u otras fallas en el seguimiento completo de las instrucciones y advertencias de nVent pueden causar el mal funcionamiento del producto, daños a la propiedad, lesiones corporales graves y la muerte y/o anular la garantía.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[schroff.nvent.com](http://schroff.nvent.com)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[schroff.nvent.com](http://schroff.nvent.com)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[schroff.nvent.com](http://schroff.nvent.com)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[schroff.nvent.com](http://schroff.nvent.com)



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**