



NVENT CADDY MACROFIX PLUS NI EZ WITH EASY CLOSURE



CERTIFICATIONS



FEATURES

Contains easy closing mechanism

Plastic washers help prevent crushing the CPVC or plastic pipe and assure a floating fit

Flared edges and specially designed welding area help protect CPVC piping

Ideal for installations where space is limited and require services to be ran close to the attachment surface

Suitable for 3/4" - 2" (20 - 50 DN) steel sprinkler pipe

Eliminates the need to seismically brace when drops are kept within 6" (150 mm) of the attachment surface

Combo head bolt works with slotted, hex, or Phillips drivers

Conforms with Manufacturers Standardization Society (MSS) SP-58 (Type 12)

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/2


Catalog Number	Article Number	Pipe Size	Pipe Size Range	NB/DN	Outer Diameter (OD)	Rod Size (RS)
MPZ020	595052	1/2"	0.5 in	15	20.0 - 21.3 mm	10
MPZ025	595053	3/4"	0.75 in	20	25.0 - 26.9 mm	10
MPZ032	595054	1"	1 in	25	32.0 - 33.7 mm	10
MPZ040	595056	1 1/4"	1.25 in min	32	40.0 - 42.4 mm	10
MPZ050	595057	1 1/2"	1.5 in	40	48.3 - 50 mm	10
MPZ063	595059	2"	2 in min	50	60.3 - 63 mm	10
MPZ075	595061	2 1/2"	2.5 in	65	75.0 - 76.1 mm	10

Table 2/2

Catalog Number	Article Number	Width (W)	Thickness (T)	Static Load (F)	Certifications
MPZ020	595052	30 mm	1.5 mm	1125N	AON Fire Protection, BB019, pipe hangers
MPZ025	595053	30 mm	1.5 mm	1125N	AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components
MPZ032	595054	30 mm	1.5 mm	1125N	AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components
MPZ040	595056	30 mm	1.5 mm	1125N	AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components
MPZ050	595057	30 mm	2 mm	1725N	AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components

CatalogNumber	Article Number	Width (W)	Thickness (T)	Static Load (F)	Certifications
MPZ063	595059	30 mm	2 mm	1725N	AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components
MPZ075	595061	30 mm	2 mm	1725N	

DIAGRAMS

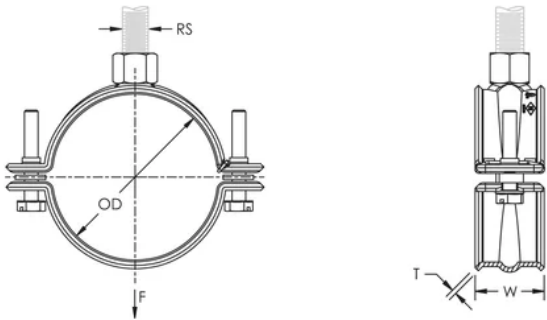

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America +1.800.753.9221 Option 1 – Customer Care Option 2 – Technical Support	Europe Netherlands: +31 800-0200135 France: +33 800 901 793	Europe Germany: 800 1890272 Other Countries: +31 13 5835404	APAC Shanghai: + 86 21 2412 1618/19 Sydney: +61 2 9751 8500
---	--	--	--