


CRIMPING COMPRESSION TOOL DIE, TYPE ML, HEAVY-DUTY DIN46235, #7  
STRANDED-1/0 STRANDED, 10 MM<sup>2</sup> STRANDED-50 MM<sup>2</sup> STRANDED

CATALOG NUMBER

**PKML1050**

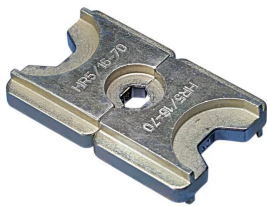

FEATURES

Suitable for cable lugs and connectors

PRODUCT ATTRIBUTES

Article Number: 716993

Lug/Connector Type: Heavy-Duty DIN46235

Conductor Size: #7 Stranded - 1/0 Stranded; 10 mm<sup>2</sup> Stranded - 50 mm<sup>2</sup> Stranded

Crimping Width: 5mm

Tool: MLB

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**