

BRANCH LINE RESTRAINT PIPE ATTACHMENT



CERTIFICATIONS



CARATTERISTICHE

Accepts 3/8" or 1/2" (M10 or M12) threaded rod

Quick grip clamp simplifies measuring and cutting of threaded rod

Eliminates need to cut threaded rod to exact dimensions

Works with rough-cut threaded rod and eliminates pipe-side deburring

Can be installed with threaded rod above or below the service pipe

Shear-off head helps ensure correct torque and simplifies inspection

SPECIFICHE

Finitura: Electrogalvanized

Materiale: Steel

Table 1/2


Codice a catalogo	Numero articolo	NB/DN	Dimensione tubo	Diametro esterno (OD)	Lunghezza (L)	Dimensione della barra (RS)
CSBBRP0100EG	404477	25	1in	33.4mm	41.4mm	10, 12

Codice a catalogo	Numero articolo	NB/DN	Dimensione tubo	Diametro esterno (OD)	Lunghezza (L)	Dimensione della barra (RS)
CSBBRP0125EG	404478	32	1.25in	42.2mm	50mm	10, 12
CSBBRP0150EG	404479	40	1.5in	48.3mm	56.1mm	10, 12
CSBBRP0200EG	404480	50	2in	60.3mm	68.3mm	10, 12

Table 2/2

Codice a catalogo	Numero articolo	Altezza (H)	Larghezza (W)
CSBBRP0100EG	404477	73.7mm	22.2mm
CSBBRP0125EG	404478	82.6mm	22.2mm
CSBBRP0150EG	404479	88.9mm	22.2mm
CSBBRP0200EG	404480	100.3mm	22.2mm

DIAGRAMS

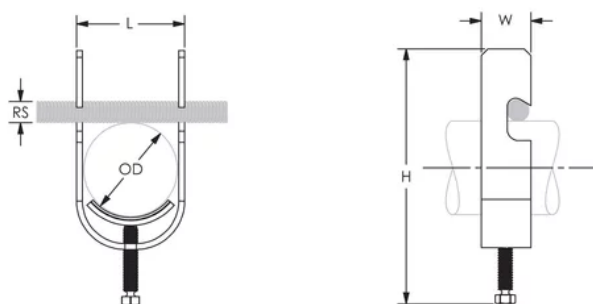

AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su www.nvent.com e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER