


FRONT PANEL 2 HP WIDE FOR COMBINED MOUNTING

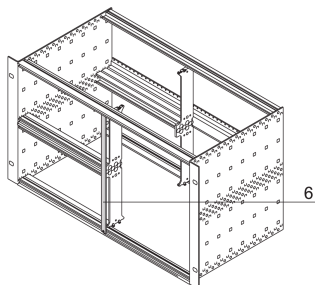

The 2 HP wide front panel covers an open slot. The non-shielded version can be fixed with screws and washers. Due to the 2 HP width, no sleeves can be used.

CERTIFICATIONS



FEATURES

Flat front panel 6 U, 2 HP, Al, 2.5 mm

SPECIFICATIONS

Table 1/2

Número catalogo	Treated Edges	Front Finish	Rear Finish	Package Quantity	Product Type	Product Family
30847-472	No	Anodized	Conductive	5	Front Panel	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO

Table 2/2

Número catalogo	Works With	Rack Height
30847-472	Subracks, Cases	6 U

ADDITIONAL PRODUCT DETAILS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

AVVERTENZA

AVVERTENZA: i prodotti nVent devono essere installati e usati solo secondo le indicazioni riportate nei fogli delle istruzioni del prodotto nVent e nei materiali di formazione. I fogli di istruzioni sono disponibili sul sito www.nvent.com e presso il vostro rappresentante locale dell'assistenza clienti di nVent. Un'installazione scorretta, l'uso improprio, l'applicazione errata o altre inosservanze delle istruzioni e delle avvertenze di nVent possono causare un malfunzionamento del prodotto, danni alle proprietà, lesioni corporee gravi e morte e/o l'annullamento della garanzia.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER