

## ATCA FRONT PANEL KIT WITH SPRING LOADING



AdvancedTCA front panel for spring-loaded IEA handle (plunger or lever style) with die-cast end piece in Al-Profile or stainless material.

### CERTIFICATIONS



### CARATTERISTICHE

Front panel (reinforced with diecast endpiece)

ATCA IEA handle with spring loading

EMC textile gasket and fixing material

### SPECIFICHE

**Accessory Type:** Front panel


Table 1/2

| Codice a catalogo | Front Finish | Rear Finish | Materiale       | Rack Height | Rack Width | Larghezza (W) |
|-------------------|--------------|-------------|-----------------|-------------|------------|---------------|
| 20818-160         | Raw          | Raw         | Stainless Steel | 8U          | 6HP        | 28.95mm       |
| 20818-161         | Raw          | Raw         | Stainless Steel | 8U          | 6HP        | 28.95mm       |
| 20818-169         | Raw          | Raw         | Aluminum        | 8U          | 6HP        | 28.95mm       |
| 20818-170         | Raw          | Raw         | Aluminum        | 8U          | 6HP        | 28.95mm       |

Table 2/2

| Codice a catalogo | Profondità (D) | Altezza (H) | Quantità per confezione | Finitura   |
|-------------------|----------------|-------------|-------------------------|------------|
| 20818-160         | 1mm            | 323.15mm    | 1                       |            |
| 20818-161         | 1mm            | 323.15mm    | 1                       |            |
| 20818-169         | 1mm            | 323.15mm    | 1                       | Passivated |
| 20818-170         | 1mm            | 323.15mm    | 1                       | Passivated |

## DIAGRAMS

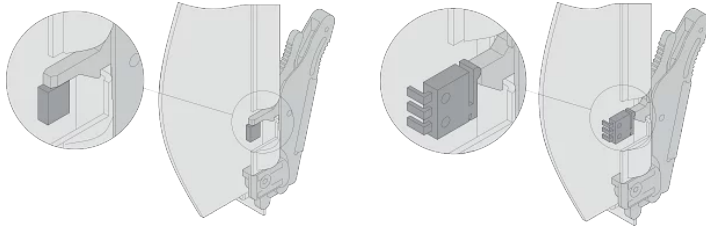

## AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su [www.nvent.com](http://www.nvent.com) e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[schroff.nvent.com](http://schroff.nvent.com)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[schroff.nvent.com](http://schroff.nvent.com)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[schroff.nvent.com](http://schroff.nvent.com)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[schroff.nvent.com](http://schroff.nvent.com)



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**