


ATCA FRONT PANEL, ST, REINFORCED, WITH SPRING LOADING

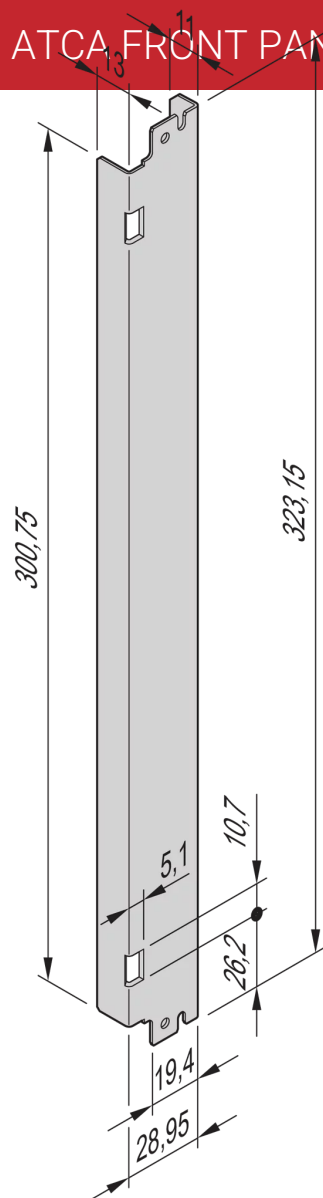

AdvancedTCA front panel for spring-loaded IEA handle with die-cast end piece.

CERTIFICATIONS

CARATTERISTICHE

Configuration: Front panel with IEA handle (with/without spring loading)

SPECIFICHE

Accessory Type: Front panel


Table 1/2

Codice a catalogo	Front Finish	Rear Finish	Materiale	Rack Height	Rack Width	Larghezza (W)
31596-791	Raw	Raw	Stainless Steel	8U	6HP	29mm
31596-792	Raw	Raw	Stainless Steel	8U	6HP	29mm

Table 2/2

Codice a catalogo	Profondità (D)	Altezza (H)	Quantità per confezione
31596-791	1mm	323.15mm	1
31596-792	1mm	323.15mm	1

DIAGRAMS

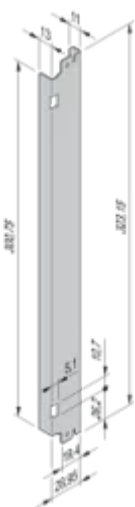

AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su www.nvent.com e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.

North America

All locations

+1.763.422.2661

Chat with us:

schroff.nvent.com

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

schroff.nvent.com

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

schroff.nvent.com



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER