


SOCKET STRIP, IEC C19

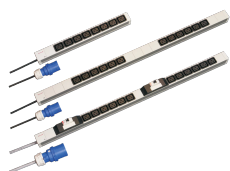

Modular, compact PDU with many function elements. Using a 1 U by 1 U aluminum chassis the PDU can easily be integrated in a rack with IEC C19 outlets.

CERTIFICATIONS



CARATTERISTICHE

Socket strips with C19 IEC sockets

Socket strips can be rotated through all four directions (in 90° increments) during installation

Connecting cable 2 m, with connector in accordance with IEC 60309

Mounting height 1 U

SPECIFICHE

Table 1/2

Codice a catalogo	Product Type	Tipo di presa	Socket Quantity	Switched Outlets	Colore	Tensione AC
60110-280	Socket Strip	IEC C19	8	No	Grey	230V
60110-281	Socket Strip	IEC C19	12	No	Grey	230V
60110-282	Socket Strip	IEC C19	12	No	Grey	230V

Table 2/2

Codice a catalogo	Altezza	Length	Profondità	Materiale	Finitura	Quantità per confezione
-------------------	---------	--------	------------	-----------	----------	-------------------------

60110-280	44mm	438.5mm	44mm	Aluminum, Polyamide	Anodized	1
60110-281	44mm	947.5mm	44mm	Aluminum, Polyamide	Anodized	1
60110-282	44mm	947.5mm	44mm	Aluminum, Polyamide	Anodized	1

ADDITIONAL PRODUCT DETAILS

Please order bracket for vertical mounting separately.

AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su www.nvent.com e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:
nVent.com **CADDY** **ERICO** **HOFFMAN** **RAYCHEM** **SCHROFF**
TRACER