

ANGULAR POURING BASIN, SIDE FILL, VARIABLE UPPER COMPONENT



Side fill pouring basins are used when interferences of the structure will not allow top filling of the sleeve. Variable angle side fill pouring basins are used when one of the predefined angle pouring basins is not available or when a project has multiple reinforcing steel angles.

The upper component is universal to all sleeve sizes and is always used in conjunction with the bottom component.

FEATURES

Made from heat-resistant graphite

Durable, re-usable and long lasting

SPECIFICATIONS

Table 1/2

Numero catalogo	Materiale	Diametro (Ø)	Lunghezza 1 (L1)	Length 2 (L2)	Larghezza (Largh.)	Altezza 1 (H1)
RBWS2468	Grafite	58 mm	159 mm	114 mm	76 mm	273mm

Table 2/2

Numero catalogo	Height 2 (H2)
RBWS2468	102mm

ADDITIONAL PRODUCT DETAILS


RBWS2468 pouring basins require one RBW350 and one RBW734 pouring basin frame and one RBS5000 bolt retainer (sold separately).

Contact nVent LENTON for assistance in sleeve selection.

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System instruction manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

DIAGRAMS

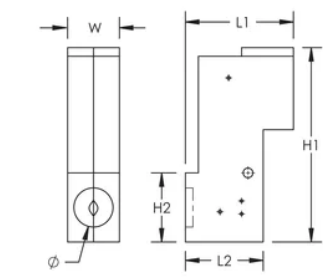

AVVERTENZA

AVVERTENZA: i prodotti nVent devono essere installati e usati solo secondo le indicazioni riportate nei fogli delle istruzioni del prodotto nVent e nei materiali di formazione. I fogli di istruzioni sono disponibili sul sito www.nvent.com e presso il vostro rappresentante locale dell'assistenza clienti di nVent. Un'installazione scorretta, l'uso improprio, l'applicazione errata o altre inosservanze delle istruzioni e delle avvertenze di nVent possono causare un malfunzionamento del prodotto, danni alle proprietà, lesioni corporee gravi e morte e/o l'annullamento della garanzia.

America del Nord

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical Support

Europa

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europa

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER