


EUROPACPRO 19" SUBRACK KIT FOR RAILWAY, RETROFIT SHIELDING, SNCF

Subrack for Railway applications, conform to SNCF Standard, non-shielded versions.

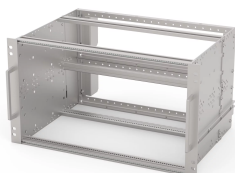

CERTIFICATIONS



FEATURES

SNCF listed, EuropacPRO-fer, tested to NF F 61-005 and NF F 60-002

The 19" bracket is firmly fixed to the side panel (tox-cold welded) and is especially suited for high mechanical stresses (vibration resistance)

Lateral support bars to NFF standard facilitate insertion of subrack into the (cabinet) frame. The double 19" screwing position adds to additionally safety (NFF standard)

IP 20, in accordance with IEC 60529

Modifications such as cutouts, different finishes or dimensions available

Supplied as space-saving flat-pack

Aluminum construction

Horizontal rail type "Heavy"

SPECIFICATIONS

Table 1/3

Numero catalogo	For Mounting	Board Depth	EMC Gasket Type	EMC Shielding	Rack Width	Handle Included
21500-027	Backplane	220 mm	Textile	No	84 HP	Si.

Numero catalogo	ForMounting	Board Depth	EMC Gasket Type	EMC Shielding	Rack Width	Handle Included
21500-029	Backplane	220 mm	Textile	No	84 HP	Si.
21500-067	Backplane	220 mm	Textile	No	36 HP	Si.
21500-070	Backplane	220 mm	Textile	No	36 HP	Si.

Table 2/3						
Numero catalogo	Package Quantity	Product Type	Rack Height	È conforme a	Montaggio	Profondità
21500-027	1	Subrack/Chassis	6 U	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	Rack	320 mm
21500-029	1	Subrack/Chassis	3 U	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	Rack	320 mm
21500-067	1	Subrack/Chassis	3 U	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	Rack	320 mm
21500-070	1	Subrack/Chassis	6 U	IEC 60297-3-103, SNCF NFF 61005, SNCF NFF 60002	Rack	320 mm

Table 3/3			
Numero catalogo	Carico statico	Shock and Vibration Tolerance	Certificazioni
21500-027	15 kgf	5 g (force)	RoHS, SNCF
21500-029	15 kgf	5 g (force)	RoHS, SNCF
21500-067	15 kgf	5 g (force)	RoHS
21500-070	15 kgf	5 g (force)	RoHS

ADDITIONAL PRODUCT DETAILS

Test reports are available online.

Fer = ferroviaire = French Railways, 1 T = 4 HP = 20.32 mm Receptacle/mounting frame for subracks, stainless steel, 9 T or 21 T on request.

Receptacle/mounting frame for subracks, stainless steel, 9 T or 21 T on request.

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

AVVERTENZA

AVVERTENZA: i prodotti nVent devono essere installati e usati solo secondo le indicazioni riportate nei fogli delle istruzioni del prodotto nVent e nei materiali di formazione. I fogli di istruzioni sono disponibili sul sito www.nvent.com e presso il vostro rappresentante locale dell'assistenza clienti di nVent. Un'installazione scorretta, l'uso improprio, l'applicazione errata o altre inosservanze delle istruzioni e delle avvertenze di nVent possono causare un malfunzionamento del prodotto, danni alle proprietà, lesioni corporee gravi e morte e/o l'annullamento della garanzia.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER