


DOUBLE TEST SOCKET, Ø 2 MM

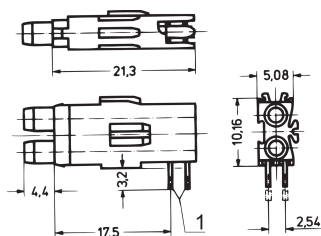

Double test sockets for mounting plane 1 and 2, short and long type.

Solder temperature should only be applied for a maximum of 5 seconds. The plastic body should be protected from the solder wave when wave soldering.

CERTIFICATIONS



CARATTERISTICHE

Double test sockets for Front Element System

SPECIFICHE

Table 1/2

Codice a catalogo	Tipo	Diameter	Tensione AC	Corrente massima	Test Voltage @ 50 Hz	Temperatura ambiente
69004-089	Long, Mounting Plane 1	2mm	30V	1A	1kV	-25 to 70°C
69004-090	Long, Mounting Plane 2	2mm	30V	1A	1kV	-25 to 70°C
69004-131	Short, Mounting Plane 1	2mm	30V	1A	1kV	-25 to 70°C

Table 2/2

Codice a catalogo	Solder Temperature	Indice di infiammabilità	Quantità per confezione
69004-089	260°C	UL® 94V-0	1
69004-090	260°C	UL® 94V-0	10
69004-131	260°C	UL® 94V-0	1

ADDITIONAL PRODUCT DETAILS

Dimensions of connecting pins: 0.3 × 0.6 mm.

Required front panel drill hole: Ø 4 mm.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su www.nvent.com e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER