


GUIDE RAIL WITH CODING, PREASSEMBLED ESD CLIP FOR COMPACTPCI/ VME64X, PC

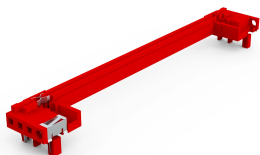

CERTIFICATIONS



CARATTERISTICHE

NEW generation with coding type plastic guide rails for reliable retention of PCBs or plug-in units

Significantly increased stability, due to an optimized design and high quality material (PC)

Improved fire safety properties, fulfills EN 45545-2 requirement sets R22, R23 and R24 with HL3

"Halogen-Free", according to IEC 61249-2-21

Can be clipped into horizontal rails (Al extrusion) or into 1.5 mm thick plates

Can be bolted to the horizontal rails Type H and R for higher shock and vibration requirements

ESD clip for an conductive contact between PCB and horizontal rail preassembled

Storage temperature: from -40 °C ... 130 °C

SPECIFICHE

Table 1/2

Codice a catalogo	Tipo	Works With	Board Depth	Materiale	Colore	Quantità per confezione
-------------------	------	------------	-------------	-----------	--------	-------------------------

24568-847	Coding and Preassembled ESD Clips	Subracks, Cases, 19" Chassis, Systems	160mm	Fiber-Reinforced Plastic	Red	10
24568-848	Coding and Preassembled ESD Clips	Subracks, Cases, 19" Chassis, Systems	160mm	Fiber-Reinforced Plastic	Grey	10
24568-850	Coding and Preassembled ESD Clips	Subracks, Cases, 19" Chassis, Systems	160mm	Fiber-Reinforced Plastic	Red	10
24568-851	Coding and Preassembled ESD Clips	Subracks, Cases, 19" Chassis, Systems	160mm	Fiber-Reinforced Plastic	Grey	10
24568-853	Coding and Preassembled ESD Clips	Subracks, Cases, 19" Chassis, Systems	70mm	Fiber-Reinforced Plastic	Red	10
24568-854	Coding and Preassembled ESD Clips	Subracks, Cases, 19" Chassis, Systems	70mm	Fiber-Reinforced Plastic	Grey	10
24568-855	Coding and Preassembled ESD Clips	Subracks, Cases, 19" Chassis, Systems	70mm	Fiber-Reinforced Plastic	Red	10
24568-856	Coding and Preassembled ESD Clips	Subracks, Cases, 19" Chassis, Systems	70mm	Fiber-Reinforced Plastic	Grey	10

Table 2/2

Codice a catalogo	È conforme a	Groove Width
24568-847	EN 45545-2	2
24568-848	EN 45545-2	2
24568-850	EN 45545-2	2
24568-851	EN 45545-2	2
24568-853	EN 45545-2	2
24568-854	EN 45545-2	2
24568-855	EN 45545-2	2
24568-856	EN 45545-2	2

ADDITIONAL PRODUCT DETAILS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su www.nvent.com e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER