


STATIC HANDLE ALU-PROFILE IN TRAPEZOID FORM

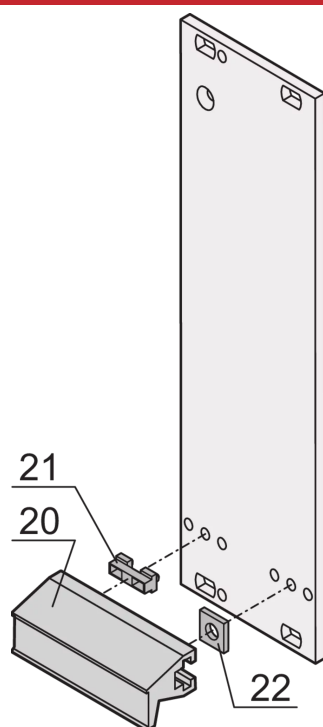

The static Alu-profile handle, trapezoid form can be mounted to a front panel for extraction of the PCB.

CERTIFICATIONS



CARATTERISTICHE

Aluminium profile handle

SPECIFICHE

Table 1/2

Codice a catalogo	Product Type	Tipo	Works With	Tipo di maniglia	Rack Width	Larghezza (W)
20809-281	Handle	Static	Front Panels	Aluminum Profile	3HP	13.8mm

Codice a catalogo	ProductType	Tipo	Works With	Tipo di maniglia	Rack Width	Larghezza (W)
20809-282	Handle	Static	Front Panels	Aluminum Profile	4HP	18.9mm
20809-283	Handle	Static	Front Panels	Aluminum Profile	5HP	24mm
20809-284	Handle	Static	Front Panels	Aluminum Profile	6HP	29mm
20809-285	Handle	Static	Front Panels	Aluminum Profile	7HP	34.1mm
20809-286	Handle	Static	Front Panels	Aluminum Profile	8HP	39.2mm
20809-287	Handle	Static	Front Panels	Aluminum Profile	9HP	44.3mm
20809-288	Handle	Static	Front Panels	Aluminum Profile	10HP	49.4mm
20809-289	Handle	Static	Front Panels	Aluminum Profile	12HP	59.6mm
20809-290	Handle	Static	Front Panels	Aluminum Profile	14HP	69.7mm
20809-291	Handle	Static	Front Panels	Aluminum Profile	21HP	105.2mm
20809-292	Handle	Static	Front Panels	Aluminum Profile	28HP	140.8mm
20809-293	Handle	Static	Front Panels	Aluminum Profile	42HP	212mm
30809-428	Handle	Static	Front Panels	Aluminum Profile		1000mm


Table 2/2				
Codice a catalogo	Materiale	Colore	Quantità per confezione	Finitura
20809-281	Aluminum	Silver	1	Anodized
20809-282	Aluminum	Silver	1	Anodized
20809-283	Aluminum	Silver	1	Anodized
20809-284	Aluminum	Silver	1	Anodized
20809-285	Aluminum	Silver	1	Anodized
20809-286	Aluminum	Silver	1	Anodized
20809-287	Aluminum	Silver	1	Anodized
20809-288	Aluminum	Silver	1	Anodized
20809-289	Aluminum	Silver	1	Anodized

Codice a catalogo	Materiale	Colore	Quantità per confezione	Finitura
20809-290	Aluminum	Silver	1	Anodized
20809-291	Aluminum	Silver	1	Anodized
20809-292	Aluminum	Silver	1	Anodized
20809-293	Aluminum	Silver	1	Anodized
30809-428	Aluminum	Silver	1	Anodized

ADDITIONAL PRODUCT DETAILS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMS

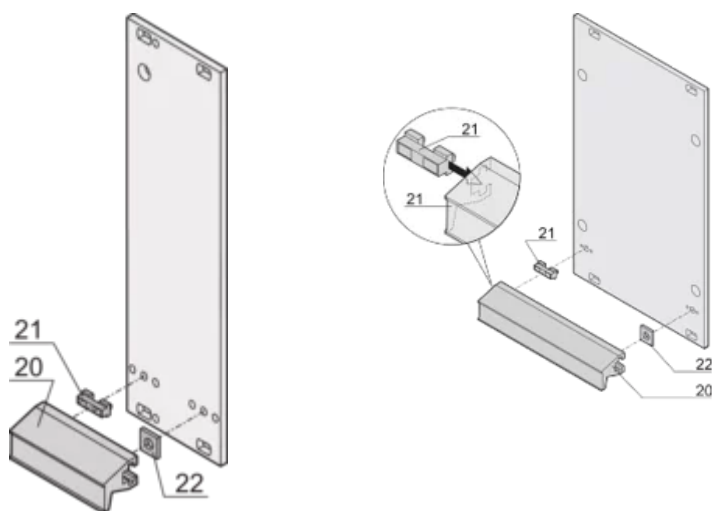

AVVERTIMENTO

I prodotti nVent devono essere installati e utilizzati solo come indicato nelle schede istruzioni e nei materiali di formazione di nVent. Le schede istruzioni sono disponibili su www.nvent.com e presso il vostro rappresentante del servizio clienti nVent. Un'installazione scorretta, un uso improprio, un'applicazione errata o qualsiasi altro mancato rispetto completo delle istruzioni e degli avvertimenti di nVent può causare malfunzionamenti del prodotto, danni alla proprietà, gravi lesioni personali e morte e/o annullare la vostra garanzia.

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER