


ABS ADJUSTABLE BUSBAR SUPPORT-ISOLATOR MODULE

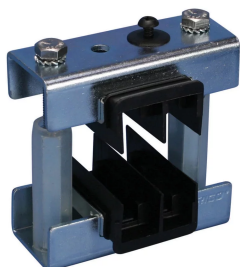

CERTIFICATIONS



FEATURES

Modules provide flexibility to select distance between phases and supports

Extremely robust construction

Halogen free insulators

RoHS compliant

SPECIFICATIONS

Table 1/2

Catalogusnummer	Artikelnummer	Typical Application Current Rating	Busbars per Phase	Busbar Thickness	Breedte rail	Max Working Voltage, IEC (Ui)
ABS1-5MOD	560860	1,700 A Max	1	5 mm	50 – 125 mm	1,000 VAC, 1,500 VDC


Table 2/2

Catalogusnummer	Artikelnummer	Werktemperatuur	Breedte (B)	Gewicht
ABS1-5MOD	560860	-40 to 130 °C	74 mm	0.640 kg

ADDITIONAL PRODUCT DETAILS

ABS Adjustable Busbar Support High Ampacity Kit available to support up to 200 mm (7.87") busbar width for applications up to 7400 A.

DIAGRAMS

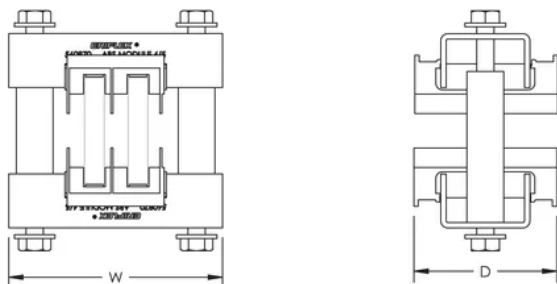

WAARSCHUWING

Producten van nVent moeten worden geïnstalleerd en gebruikt op de manier zoals is aangegeven in de nVent productinformatiebladen en trainingsmaterialen. U kunt de productinformatiebladen downloaden van www.nvent.com of opvragen bij uw nVent-klantenservice. Door onjuist installeren, verkeerd gebruik, verkeerde toepassing of enige andere handeling in strijd met de instructies en waarschuwingen van nVent kan het product mogelijk niet correct werken, ernstig of fataal letsel en materiële schade veroorzaken en/of uw garantie ongeldig maken.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER