


FRONT PANEL, SHIELDED, BOTTOM HINGED

U-profile front panel bottom hinged for textile gasket.

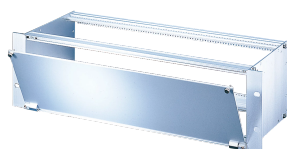

CERTIFICATIONS



FEATURES

U-profile front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

Shielded, U front panel with textile EMC gasket

Suitable for subracks (EuropacPRO) and cases (RatiopacPRO, PropacPRO, CompacPRO)

SPECIFICATIONS

Table 1/3

Catalogusnummer	EMC Gasket Type	Treated Edges	Front Finish	Rear Finish	EMC Shielding	Rack Width
20848-599	Textile	Nee	Anodized	Conductive	No (Retrofittable)	42 HP
20848-600	Textile	Nee	Anodized	Conductive	No (Retrofittable)	63 HP
20848-601	Textile	Nee	Anodized	Conductive	No (Retrofittable)	84 HP
20848-602	Textile	Nee	Anodized	Conductive	No (Retrofittable)	42 HP

Catalogusnummer	EMC Gasket Type	Treated Edges	Front Finish	Rear Finish	EMC Shielding	Rack Width
20848-603	Textile	Nee	Anodized	Conductive	No (Retrofittable)	63 HP
20848-604	Textile	Nee	Anodized	Conductive	No (Retrofittable)	84 HP
20848-605	Textile	Nee	Anodized	Conductive	No (Retrofittable)	42 HP
20848-606	Textile	Nee	Anodized	Conductive	No (Retrofittable)	63 HP
20848-607	Textile	Nee	Anodized	Conductive	No (Retrofittable)	84 HP
20848-608	Textile	Nee	Anodized	Conductive	No (Retrofittable)	28 HP
20848-696	Textile	Nee	Anodized	Conductive	No (Retrofittable)	28 HP

Table 2/3						
Catalogusnummer	Package Quantity	Hoogte	Product Type	Type	Rack Height	Breedte
20848-599	1	128.4 mm	Front Panel	Front Panel without Handle	3 U	213 mm
20848-600	1	128.4 mm	Front Panel	Front Panel without Handle	3 U	319.7 mm
20848-601	1	128.4 mm	Front Panel	Front Panel without Handle	3 U	426.4 mm
20848-602	1	261.8 mm	Front Panel	Front Panel without Handle	6 U	213 mm
20848-603	1	261.8 mm	Front Panel	Front Panel without Handle	6 U	319.7 mm
20848-604	1	261.8 mm	Front Panel	Front Panel without Handle	6 U	426.4 mm
20848-605	1	172.9 mm	Front Panel	Front Panel without Handle	4 U	213 mm
20848-606	1	172.9 mm	Front Panel	Front Panel without Handle	4 U	319.7 mm
20848-607	1	172.9 mm	Front Panel	Front Panel without Handle	4 U	426.4 mm
20848-608	1	128.4 mm	Front Panel	Front Panel without Handle	3 U	141.9 mm
20848-696	1	261.8 mm	Front Panel	Front Panel without Handle	6 U	141.9 mm

Table 3/3

Catalogusnummer	Voldoet aan	Montage	Materiaal
20848-599	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminium
20848-600	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminium
20848-601	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminium
20848-602	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminium
20848-603	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminium
20848-604	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminium
20848-605	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminium
20848-606	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminium
20848-607	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminium
20848-608	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminium
20848-696	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminium

ADDITIONAL PRODUCT DETAILS

Front panel can be removed in opened position (> 135°).

WAARSCHUWING

Producten van nVent moeten worden geïnstalleerd en gebruikt op de manier zoals is aangegeven in de nVent productinformatiebladen en trainingsmaterialen. U kunt de productinformatiebladen downloaden van www.nvent.com of opvragen bij uw nVent-klantenservice. Door onjuist installeren, verkeerd gebruik, verkeerde toepassing of enige andere handeling in strijd met de instructies en waarschuwingen van nVent kan het product mogelijk niet correct werken, ernstig of fataal letsel en materiële schade veroorzaken en/of uw garantie ongeldig maken.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER