

BRANCH LINE RESTRAINT STRUCTURE ATTACHMENT TO WOOD/CONCRETE



CERTIFICATIONS



KENMERKEN

Swivel barrel nut accepts 3/8" or 1/2" (M10 or M12) threaded rod

Attaches to wood or concrete where cracked concrete approval is not needed

SPECIFICATIES

Table 1/2

Catalogusnummer	Article Number	Materiaal	Afwerking	Lengte (metrisch) (L)	Formaat stang (RS)	Diameter schroef (Sc)
CSBBRS2MEG	402240	Steel	Electrogalvanized	40.4mm	10, 12	0.25in


Table 2/2

Catalogusnummer	Article Number	Hoogte (H)	Lengte schroef (L)	Breedte (W)	Diameter boorkop
CSBBRS2MEG	402240	28.2mm	44.5mm	26.9mm	5mm

ADDITIONAL PRODUCT DETAILS

Branch line structural attachments are for restraint only and not for the hanging of fire sprinkler piping.

DIAGRAMS

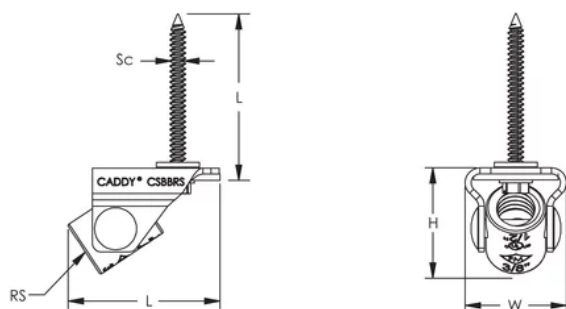

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER