


GUIDE RAIL WITH CODING, PREASSEMBLED ESD CLIP FOR COMPACTPCI/ VME64X, PC

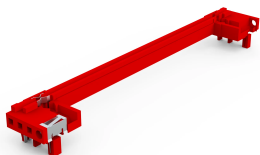

CERTIFICATIONS



KENMERKEN

NEW generation with coding type plastic guide rails for reliable retention of PCBs or plug-in units

Significantly increased stability, due to an optimized design and high quality material (PC)

Improved fire safety properties, fulfills EN 45545-2 requirement sets R22, R23 and R24 with HL3

"Halogen-Free", according to IEC 61249-2-21

Can be clipped into horizontal rails (Al extrusion) or into 1.5 mm thick plates

Can be bolted to the horizontal rails Type H and R for higher shock and vibration requirements

ESD clip for an conductive contact between PCB and horizontal rail preassembled

Storage temperature: from -40 °C ... 130 °C

SPECIFICATIES

Table 1/2

Catalogusnummer	Type	Works With	Board Depth	Materiaal	Kleur	Aantal in verpakking
-----------------	------	------------	-------------	-----------	-------	----------------------

24568-847	Coding and Preassembled ESD Clips	Subracks, Cases, 19" Chassis, Systems	160mm	Fiber-Reinforced Plastic	Red	10
24568-848	Coding and Preassembled ESD Clips	Subracks, Cases, 19" Chassis, Systems	160mm	Fiber-Reinforced Plastic	Grey	10
24568-850	Coding and Preassembled ESD Clips	Subracks, Cases, 19" Chassis, Systems	160mm	Fiber-Reinforced Plastic	Red	10
24568-851	Coding and Preassembled ESD Clips	Subracks, Cases, 19" Chassis, Systems	160mm	Fiber-Reinforced Plastic	Grey	10
24568-853	Coding and Preassembled ESD Clips	Subracks, Cases, 19" Chassis, Systems	70mm	Fiber-Reinforced Plastic	Red	10
24568-854	Coding and Preassembled ESD Clips	Subracks, Cases, 19" Chassis, Systems	70mm	Fiber-Reinforced Plastic	Grey	10
24568-855	Coding and Preassembled ESD Clips	Subracks, Cases, 19" Chassis, Systems	70mm	Fiber-Reinforced Plastic	Red	10
24568-856	Coding and Preassembled ESD Clips	Subracks, Cases, 19" Chassis, Systems	70mm	Fiber-Reinforced Plastic	Grey	10

Table 2/2

Catalogusnummer	Conform	Groove Width
24568-847	EN 45545-2	2
24568-848	EN 45545-2	2
24568-850	EN 45545-2	2
24568-851	EN 45545-2	2
24568-853	EN 45545-2	2
24568-854	EN 45545-2	2
24568-855	EN 45545-2	2
24568-856	EN 45545-2	2

ADDITIONAL PRODUCT DETAILS

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

WAARSCHUWING

nVent-producten moeten alleen worden geïnstalleerd en gebruikt zoals aangegeven in de instructiebladen en trainingsmateriaal van nVent. Instructiebladen zijn beschikbaar op www.nvent.com en bij uw nVent klantenservicevertegenwoordiger. Onjuiste installatie, misbruik, verkeerde toepassing of ander falen om de instructies en waarschuwingen van nVent volledig te volgen, kan leiden tot productstoringen, schade aan eigendommen, ernstig lichamelijk letsel en de dood en/of uw garantie ongeldig maken.

North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER