

## BRANCH LINE RESTRAINT PIPE ATTACHMENT



### CERTIFICATIONS



### FUNKSJONER

Accepts 3/8" or 1/2" (M10 or M12) threaded rod

Quick grip clamp simplifies measuring and cutting of threaded rod

Eliminates need to cut threaded rod to exact dimensions

Works with rough-cut threaded rod and eliminates pipe-side deburring

Can be installed with threaded rod above or below the service pipe

Shear-off head helps ensure correct torque and simplifies inspection

### SPESIFIKASJONER

**Finish:** Electrogalvanized

**Materiale:** Steel

Table 1/2


| Katalognum<br>mer | Article<br>Number | NB/DN | Rørstørrelse | Ytre<br>diameter<br>(OD) | Lengde (L) | Stagstørrelse<br>(RS) |
|-------------------|-------------------|-------|--------------|--------------------------|------------|-----------------------|
| CSBBRP0100EG      | 404477            | 25    | 1in          | 33.4mm                   | 41.4mm     | 10, 12                |

| Katalognummer | Article Number | NB/DN | Rørstørrelse | Ytre diameter (OD) | Lengde (L) | Stagstørrelse (RS) |
|---------------|----------------|-------|--------------|--------------------|------------|--------------------|
| CSBBRP0125EG  | 404478         | 32    | 1.25in       | 42.2mm             | 50mm       | 10, 12             |
| CSBBRP0150EG  | 404479         | 40    | 1.5in        | 48.3mm             | 56.1mm     | 10, 12             |
| CSBBRP0200EG  | 404480         | 50    | 2in          | 60.3mm             | 68.3mm     | 10, 12             |

Table 2/2

| Katalognummer | Article Number | Høyde (H) | Bredde (W) |
|---------------|----------------|-----------|------------|
| CSBBRP0100EG  | 404477         | 73.7mm    | 22.2mm     |
| CSBBRP0125EG  | 404478         | 82.6mm    | 22.2mm     |
| CSBBRP0150EG  | 404479         | 88.9mm    | 22.2mm     |
| CSBBRP0200EG  | 404480         | 100.3mm   | 22.2mm     |

## DIAGRAMS

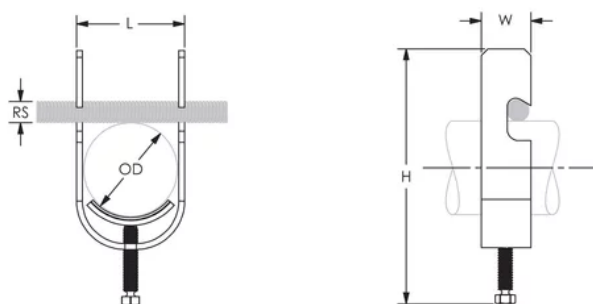

## ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på [www.nvent.com](http://www.nvent.com) og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**