


## TRC FOUR POLE DISTRIBUTION BLOCK, 630 A

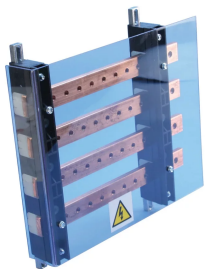

### CERTIFICATIONS



### FUNKSJONER

Transparent protection cover

Bolts included for output connections

Easy accessibility for wiring

Ready to use out of the box, saving installation time and labor

RoHS compliant

### SPESIFIKASJONER

Table 1/3

| Katalognummer | Article Number | Peak Short Circuit Current (Ipk) | Materiale                                            | Short Term Withstand Current (Icw) 1s | Line Side Number of Connections | Load Side Number of Connections |
|---------------|----------------|----------------------------------|------------------------------------------------------|---------------------------------------|---------------------------------|---------------------------------|
| TRC-630A      | 563190         | 84kA                             | Copper, Glass Fibre Reinforced Polyamide, Plexiglass | 52kA                                  | 1                               | 8                               |

Table 2/3

| Katalognummer | Article Number | Gjengestørrelse (TS) | Max Working Voltage, IEC (Ui) | Hullstørrelse (HS) | Høyde (H)   | Bredde (W) |
|---------------|----------------|----------------------|-------------------------------|--------------------|-------------|------------|
| TRC-630A      | 563190         | M8                   | 1000                          | 10mm               | 338 – 390mm | 340mm      |


Table 3/3

| Katalognummer | Article Number | Dybde (D) | A     | Komponentvekt | Flammability Rating | Samsvarer med                                                             |
|---------------|----------------|-----------|-------|---------------|---------------------|---------------------------------------------------------------------------|
| TRC-630A      | 563190         | 60mm      | 290mm | 4.8kg         | UL® 94V-0           | IEC® 60439.1,<br>IEC® 61439.1,<br>IEC® 60695-2-11 (Glow Wire Test 960 °C) |

## ADDITIONAL PRODUCT DETAILS

Line side and load side number of connections are per pole.

## DIAGRAMS

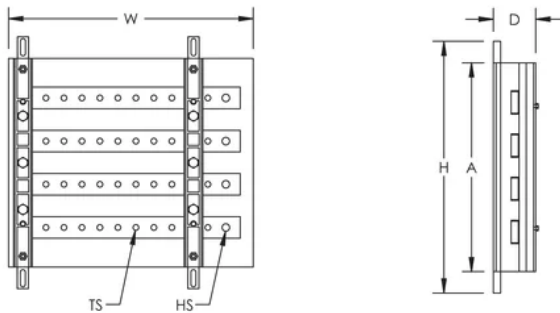

## ADVARSEL

nVent-produkter må installeres og brukes bare som beskrevet i nVent sine instruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelig på [www.nvent.com](http://www.nvent.com) og fra din nVent kundeservice-representant. Ukorrekt installasjon, misbruk, feilaktig anvendelse eller annen manglende etterlevelse av nVent sine instruksjoner og advarsler kan føre til produktfeil, skade på eiendom, alvorlige personskader og død og/eller gjøre garantien ugyldig.



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**