


ABS ISOLATORMODUL FOR JUSTERBAR SAMLESKINNESTØTTE

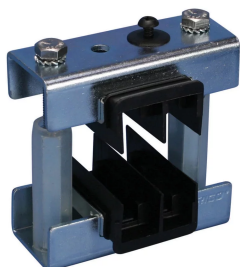

CERTIFICATIONS



FEATURES

Modules provide flexibility to select distance between phases and supports

Extremely robust construction

Halogen free insulators

RoHS compliant

SPECIFICATIONS

Table 1/2

Katalognummer	Artikkelnummer	Typical Application Current Rating	Busbars per Phase	Busbar Thickness	Samleskinne bredde	Max Working Voltage, IEC (Ui)
ABS1-5MOD	560860	1,700 A Max	1	5 mm	50 – 125 mm	1,000 VAC, 1,500 VDC

Table 2/2


Katalognummer	Artikkelnummer	Arbeidstemperatur	Bredde (B)	Tomvekt
---------------	----------------	-------------------	------------	---------

ABS1-5MOD	560860	-40 to 130 °C	74 mm	0.640 kg
-----------	--------	---------------	-------	----------

ADDITIONAL PRODUCT DETAILS

ABS Adjustable Busbar Support High Ampacity Kit available to support up to 200 mm (7.87") busbar width for applications up to 7400 A.

DIAGRAMS

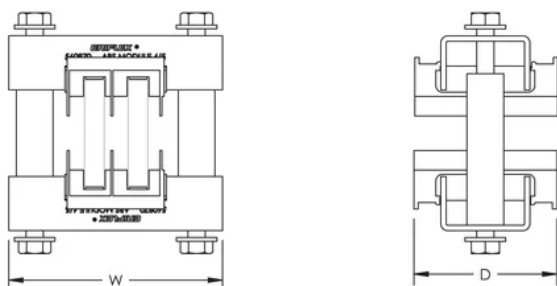

ADVARSEL

nVent-produkter skal kun installeres og brukes som angitt i nVents produktinstruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelige på www.nvent.com og fra nVent-kundeservicerepresentanten din. Feil installasjon, misbruk, feil bruk eller annen unnlatelse av å følge nVents instruksjoner og advarsler i deres helhet kan forårsake produktfeil, skade på eiendom, alvorlig personskade og død og/eller ugyldiggjøre garantien din.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER