


EUROPACPRO 19" SUBRACK KIT FOR POWER DISTRIBUTION MODULE, UNSHIELDED

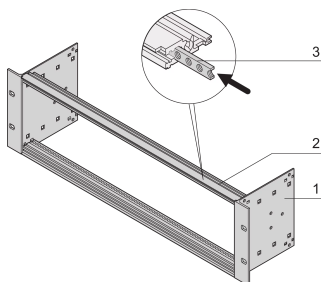

For mounting installation devices in accordance with DIN 43880 in sizes 1-3 with snap-in technology e.g. mounting sockets, circuit breakers or residual current circuit breaker. These can be fitted after the horizontal rail with lip DIN central rail (35/7.5) are fitted.

CERTIFICATIONS



FEATURES

For mounting installation devices in accordance with DIN 43880 in sizes 1-3 with snap-in technology e.g. mounting sockets, circuit breakers or residual current circuit breaker. These can be fitted after the horizontal rail with lip DIN central rail (35/7.5) are fitted

Modular frame to accept e.g. power distribution modules

Internal and external dimensions in accordance with the IEC 60297-3-101 and IEEE 1101.1 standards

Aluminium side panels

Horizontal rails type "light"

IEEE 1101.1 compatible

SPECIFICATIONS

Table 1/2

Katalognummer	For Mounting	EMC Shielding	Rack Width	Handle Included	Package Quantity	Product Type
24563-100	Power Distribution Module	Nei	84 HP	Nei	1	Subrack/Chassis

Table 2/2

Katalognummer	Rack Height	Samsvarer med	Montering	Dybde	Statisk belastning
24563-100	3 U	IEC 60297-3-103	Rack	115 mm	2.5 kgf

ADVARSEL

nVent-produkter skal kun installeres og brukes som angitt i nVents produktinstruksjonsark og opplæringsmateriell.

Instruksjonsark er tilgjengelige på www.nvent.com og fra nVent-kundeservicerepresentanten din. Feil installasjon, misbruk, feil bruk eller annen unnlatelse av å følge nVents instruksjoner og advarsler i deres helhet kan forårsake produktfeil, skade på eiendom, alvorlig personskade og død og/eller ugyldiggjøre garantien din.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER