


FRONT PANEL, UNSHIELDED, BOTTOM HINGED

Unshielded front panel bottom hinged.

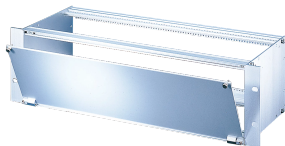

CERTIFICATIONS



FEATURES

Front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

SPECIFICATIONS

Table 1/3

Katalognummer	Treated Edges	Front Finish	Rear Finish	EMC Shielding	Rack Width	Package Quantity
20838-271	Nei	Anodized	Conductive	Nei	42 HP	1
20838-272	Nei	Anodized	Conductive	Nei	63 HP	1
20838-273	Nei	Anodized	Conductive	Nei	84 HP	1
20838-274	Nei	Anodized	Conductive	Nei	42 HP	1
20838-275	Nei	Anodized	Conductive	Nei	63 HP	1
20838-276	Nei	Anodized	Conductive	Nei	84 HP	1
20838-277	Nei	Anodized	Conductive	Nei	42 HP	1
20838-278	Nei	Anodized	Conductive	Nei	63 HP	1

Katalognummer	Treated Edges	Front Finish	Rear Finish	EMC Shielding	Rack Width	Package Quantity
20838-279	Nei	Anodized	Conductive	Nei	84 HP	1
20838-280	Nei	Anodized	Conductive	Nei	28 HP	1

Table 2/3						
Katalognummer	Høyde	Product Type	Type	Rack Height	Bredde	Samsvarer med
20838-271	128.4 mm	Front Panel	Front Panel without Handle	3 U	213 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-272	128.4 mm	Front Panel	Front Panel without Handle	3 U	319.7 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-273	128.4 mm	Front Panel	Front Panel without Handle	3 U	426.4 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-274	261.8 mm	Front Panel	Front Panel without Handle	6 U	213 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-275	261.8 mm	Front Panel	Front Panel without Handle	6 U	319.7 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-276	261.8 mm	Front Panel	Front Panel without Handle	6 U	426.4 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-277	172.9 mm	Front Panel	Front Panel without Handle	4 U	213 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-278	172.9 mm	Front Panel	Front Panel without Handle	4 U	319.7 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-279	172.9 mm	Front Panel	Front Panel without Handle	4 U	426.4 mm	IEC 60297-3-101, IEEE 1101.1/10
20838-280	128.4 mm	Front Panel	Front Panel without Handle	3 U	141.9 mm	IEC 60297-3-101, IEEE 1101.1/10

Table 3/3		
Katalognummer	Montering	Materiell
20838-271	Hinged, Bottom	Aluminium
20838-272	Hinged, Bottom	Aluminium
20838-273	Hinged, Bottom	Aluminium

Katalognummer	Montering	Materiell
20838-274	Hinged, Bottom	Aluminium
20838-275	Hinged, Bottom	Aluminium
20838-276	Hinged, Bottom	Aluminium
20838-277	Hinged, Bottom	Aluminium
20838-278	Hinged, Bottom	Aluminium
20838-279	Hinged, Bottom	Aluminium
20838-280	Hinged, Bottom	Aluminium

ADDITIONAL PRODUCT DETAILS

Front panel can be removed in opened position (> 135°).

ADVARSEL

nVent-produkter skal kun installeres og brukes som angitt i nVents produktinstruksjonsark og opplæringsmateriell. Instruksjonsark er tilgjengelige på www.nvent.com og fra nVent-kundeservicerepresentanten din. Feil installasjon, misbruk, feil bruk eller annen unnlatelse av å følge nVents instruksjoner og advarsler i deres helhet kan forårsake produktfeil, skade på eiendom, alvorlig personskade og død og/eller ugyldiggjøre garantien din.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER