


# Copper Utility Ground Plate, One Pigtail

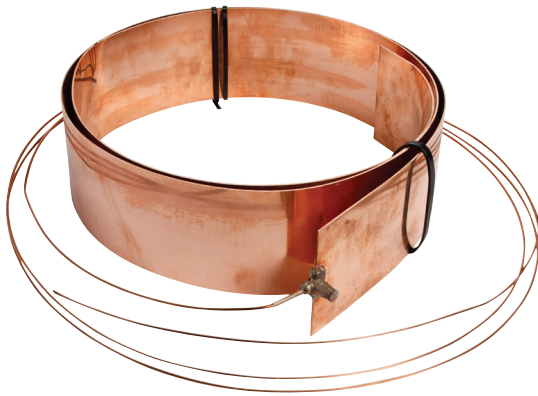

The nVent ERICO Copper Utility Ground Plate with One Pigtail is a grounding and bonding solution designed for the Irrigation industry. The pigtail is welded using a Cadweld exothermic connection to create a permanent molecular bond that will not loosen or corrode, ensuring the durability and reliability of the system. The ground plate provides a large surface area to dissipate current into the ground, which is beneficial in areas with high resistivity, such as rocky, sandy, or shallow soil conditions, where using only a ground rod may not be feasible. The pigtail provides added flexibility in the placement of the ground plate.

 
## FEATURES:

- Provides a large surface area to dissipate current into the ground
- Available in a variety of sizes and pigtail configurations

**Material:** Copper

**Insulated:** Yes

Part Number	Length 1 L1	Length 2 L2	Width W	Thickness T	Conductor Size	Insulated
UGP436GW10F15	36"	180"	4"	0.06"	#10 Solid	Yes
UGP436GW6F25	36"	300"	4"	0.06"	#6 Solid	Yes
UGP496GW6F25	96"	300"	4"	0.06"	#6 Solid	Yes
UGP4966F25	96"	300"	4"	0.06"	#6 Solid	No



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   RAYCHEM   SCHROFF**