

BRANCH LINE RESTRAINT STRUCTURE ATTACHMENT TO STEEL



CERTIFICATIONS



KENMERKEN

Swivel barrel nut accepts 3/8" or 1/2" (M10 or M12) threaded rod

Attaches to steel members with self-drilling/tapping screw

SPECYFIKACJE

Table 1/2

Numer katalogowy	Article Number	Materiał	Wykończenie	Grubość kołnierza (FT)	Długość (L)	Rozmiar pręta (RS)
CSBBRS1MEG	402239	Steel	Electrogalvanize d	2.7 – 12.7mm	40.4mm	10, 12


Table 2/2

Numer katalogowy	Article Number	Średnica śruby (Sc)	Wysokość (H)	Długość śruby (L)	Szerokość (W)
CSBBRS1MEG	402239	2.7mm	28.2mm	32mm	26.9mm

ADDITIONAL PRODUCT DETAILS

Branch line structural attachments are for restraint only and not for the hanging of fire sprinkler piping.

DIAGRAMS

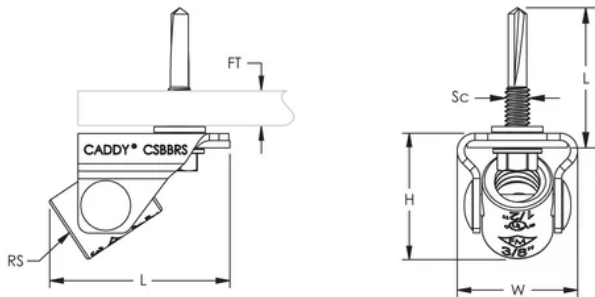

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER