


CRIMPING COMPRESSION TOOL DIE, TYPE ML, HEAVY-DUTY DIN46235, 185 MM² STRANDED, 350 KCMIL STRANDED

NUMER KATALOGOWY

PKML185

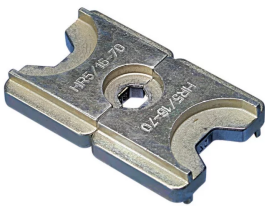

KENMERKEN

Suitable for cable lugs and connectors

ATRYBUTY PRODUKTU

Article Number: 716998

Lug/Connector Type: Heavy-Duty DIN46235

Conductor Size: 185 mm² Stranded; 350 kcmil Stranded

Crimping Width: 5mm

Tool: MLB

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER