


FRONT PANEL, SHIELDED, BOTTOM HINGED

U-profile front panel bottom hinged for textile gasket.

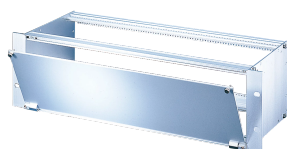

CERTIFICATIONS



FEATURES

U-profile front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

Shielded, U front panel with textile EMC gasket

Suitable for subracks (EuropacPRO) and cases (RatiopacPRO, PropacPRO, CompacPRO)

SPECIFICATIONS

Table 1/3

Numer katalogowy	EMC Gasket Type	Treated Edges	Front Finish	Rear Finish	EMC Shielding	Rack Width
20848-599	Textile	Nie	Anodized	Conductive	No (Retrofittable)	42 HP
20848-600	Textile	Nie	Anodized	Conductive	No (Retrofittable)	63 HP
20848-601	Textile	Nie	Anodized	Conductive	No (Retrofittable)	84 HP
20848-602	Textile	Nie	Anodized	Conductive	No (Retrofittable)	42 HP

Numer katalogowy	EMC Gasket Type	Treated Edges	Front Finish	Rear Finish	EMC Shielding	Rack Width
20848-603	Textile	Nie	Anodized	Conductive	No (Retrofittable)	63 HP
20848-604	Textile	Nie	Anodized	Conductive	No (Retrofittable)	84 HP
20848-605	Textile	Nie	Anodized	Conductive	No (Retrofittable)	42 HP
20848-606	Textile	Nie	Anodized	Conductive	No (Retrofittable)	63 HP
20848-607	Textile	Nie	Anodized	Conductive	No (Retrofittable)	84 HP
20848-608	Textile	Nie	Anodized	Conductive	No (Retrofittable)	28 HP
20848-696	Textile	Nie	Anodized	Conductive	No (Retrofittable)	28 HP

Table 2/3						
Numer katalogowy	Package Quantity	Wysokość	Product Type	Typ	Rack Height	Szerokość
20848-599	1	128.4 mm	Front Panel	Front Panel without Handle	3 U	213 mm
20848-600	1	128.4 mm	Front Panel	Front Panel without Handle	3 U	319.7 mm
20848-601	1	128.4 mm	Front Panel	Front Panel without Handle	3 U	426.4 mm
20848-602	1	261.8 mm	Front Panel	Front Panel without Handle	6 U	213 mm
20848-603	1	261.8 mm	Front Panel	Front Panel without Handle	6 U	319.7 mm
20848-604	1	261.8 mm	Front Panel	Front Panel without Handle	6 U	426.4 mm
20848-605	1	172.9 mm	Front Panel	Front Panel without Handle	4 U	213 mm
20848-606	1	172.9 mm	Front Panel	Front Panel without Handle	4 U	319.7 mm
20848-607	1	172.9 mm	Front Panel	Front Panel without Handle	4 U	426.4 mm
20848-608	1	128.4 mm	Front Panel	Front Panel without Handle	3 U	141.9 mm
20848-696	1	261.8 mm	Front Panel	Front Panel without Handle	6 U	141.9 mm

Table 3/3

Numer katalogowy	Zgodność z	Montaż	Materiał
20848-599	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminium
20848-600	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminium
20848-601	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminium
20848-602	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminium
20848-603	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminium
20848-604	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminium
20848-605	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminium
20848-606	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminium
20848-607	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminium
20848-608	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminium
20848-696	IEC 60297-3-101, IEEE 1101.1/10	Hinged, Bottom	Aluminium

ADDITIONAL PRODUCT DETAILS

Front panel can be removed in opened position (> 135°).

OSTRZEŻENIE

Produkty nVent powinny być instalowane i używane wyłącznie zgodnie z instrukcjami i materiałami szkoleniowymi nVent. Instrukcje są dostępne na stronie www.nvent.com oraz u przedstawiciela działu obsługi klienta firmy nVent. Nieprawidłowa instalacja, niewłaściwe użycie, niewłaściwe zastosowanie lub inne nieprzestrzeganie instrukcji i ostrzeżeń nVent może spowodować nieprawidłowe działanie produktu, uszkodzenie mienia, poważne obrażenia ciała i śmierć i/lub utratę gwarancji.



Our powerful portfolio of brands:
nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF
TRACER