

BRANCH LINE RESTRAINT STRUCTURE ATTACHMENT TO THREADED HOLE



CERTIFICATIONS



CARACTERÍSTICAS

Swivel barrel nut accepts 3/8" or 1/2" (M10 or M12) threaded rod

Attaches to concrete anchors or structural attachments with female threads

Can be used for bolting through steel

ESPECIFICAÇÕES

Acabamento: Electrogalvanized

Material: Steel

Table 1/2

Número de catálogo	Article Number	Comprimento (L)	Tamanho da haste (RS)	Diâmetro do parafuso (Sc)	Altura (H)	Comprimento do parafuso (L)
CSBBRS3EG		40.4mm	0.375, 0.5	0.375	28.2mm	19mm
CSBBRS3MEG	402241	40.4mm	10, 12	10	28.2mm	19mm

Table 2/2


Número de catálogo	Article Number	Largura (W)	Certifications
--------------------	----------------	-------------	----------------

CSBBRS3EG		26.9mm	UL, OSHPD/HCAI, FM Approved, Seismic
CSBBRS3MEG	402241	26.9mm	AON Fire Protection, Rigid Seismic, UL, FM Approved, Seismic

ADDITIONAL PRODUCT DETAILS

Branch line structural attachments are for restraint only and not for the hanging of fire sprinkler piping.

DIAGRAMS

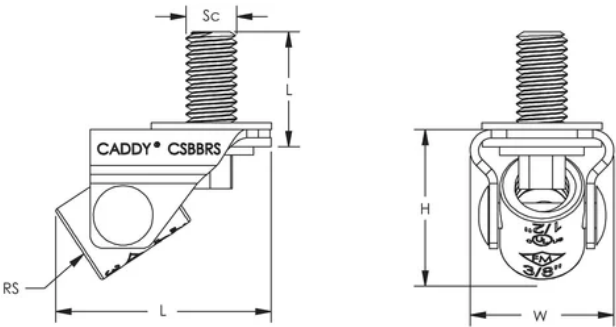

AVISO

Os produtos nVent devem ser instalados e utilizados apenas conforme indicado nas fichas de instrução do produto e materiais de treinamento da nVent. As fichas de instrução estão disponíveis em www.nVent.com e com nossos representantes de atendimento ao cliente nVent. A instalação inadequada, uso incorreto, aplicação incorreta ou outra falha qualquer em seguir completamente as instruções e avisos da nVent podem levar ao mau funcionamento do produto, danos à propriedade, lesões corporais graves e morte, e/ou anular sua garantia.